



MatixGO

IP55 cover plates

28603W - 28603G - 28603B
28604W - 28604G - 28604B

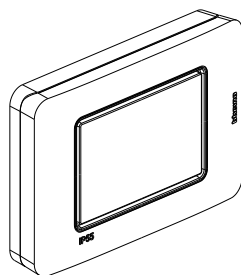

28603.

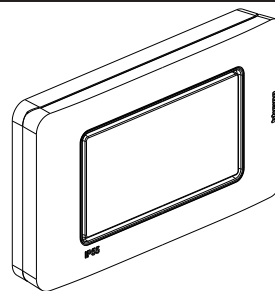

28604.

Use

IP55 cover plate for installation MatixGo range wiring devices.

Range


Designation	Item
IP55 cover plate 3 modules	☐ 28603W
	☐ 28603G
	☐ 28603B
IP55 cover plate 4 modules	☐ 28604W
	☐ 28604G
	☐ 28604B

Colors: ☐ White ☐ Grey ☐ Black

Technical characteristics

- **Protection index**
considering door closed, penetration by solid bodies/liquid: IP55
 - **Mechanical characteristics**
Impact test: IK 04
 - **Material characteristics**
Materials:
 - Case : rigid part PC (polycarbonate) + gasket in polyurethane foam
 - Door : rigid part in PC (polycarbonate) + flexible transparent part acrylic block copolymer elastomer.
- UV resistant.
Halogen free.
- Self-extinguishing: 650° C / 30 s for parts made of insulating materials
- **Climatic characteristics**
Storage temperature: - 10° C to + 70° C
Use temperature: - 5° C to + 35° C

Overall dimensions (mm)

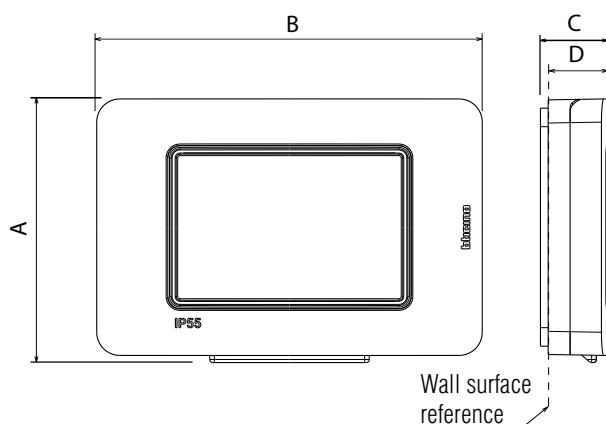

	A	B	C	D
28603W,28603G,28603B	85.3	124.7	21.6	19.1
28604W,28604G,28604B	85.3	147.2	21.6	19.1

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC CEI EN 60670-1
Refer to e.catalogue.