



MatixGO

USB Type AA & AC chargers with duplex tamper-resistant receptacles 15A 125V

JW4188AA - JG4188AA - JB4188AA
JW4188AC - JG4188AC - JB4188AC

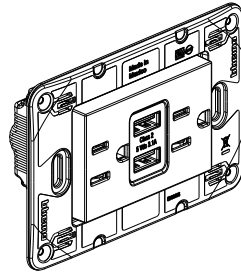

J_4188AA

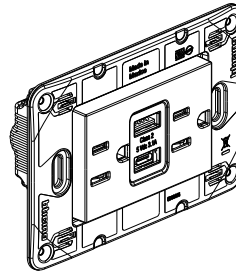

J_4188AC

Use


USB Type AA & AC chargers with duplex tamper-resistant receptacles
15A 125V

Range

Designation	Cat. Nos.
Mixed socket composed of:	
- duplex US standard socket 15 A - 125 V~	☐ JW4188AA
- double USB socket - type A + type A	☐ JG4188AA
	☐ JB4188AA
Mixed socket composed of:	
- duplex US standard socket 15 A - 125 V~	☐ JW4188AC
- double USB socket - type A + type C	☐ JG4188AC
	☐ JB4188AC

Colours code: ☐ White ☐ Grey ☐ Black

Overall dimensions (mm)

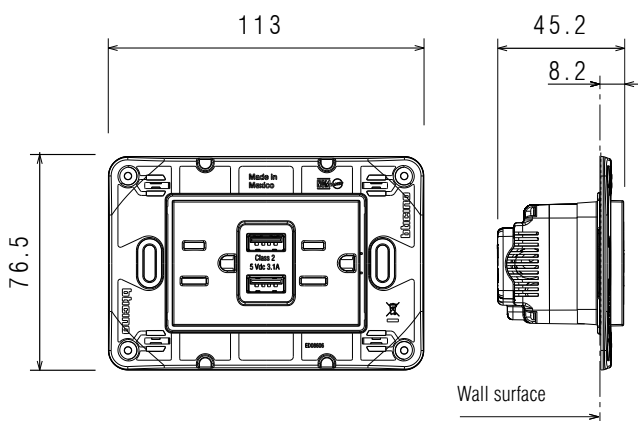

Connection

- **Duplex US standard socket**
Terminal type: screw clamp
Terminal capacity: 2 x 4 mm² max
Stripping length: 13 mm
Compatible with flexible or rigid cables
- **Type USB socket**
Prewired socket

Technical characteristics

- Protection index:

(considering a complete installation, including cover plate)
Penetration by solid bodies/liquid: IP20D

- Mechanical characteristics:

Impact test: IK 04

- Material characteristics:

Key cover: polycarbonate PC
Case: nylon PA
UV resistant
Self-extinguishing: 850°C / 30 s for insulating parts holding live parts in place
650°C / 30 s for other parts made of insulating materials

- Electrical characteristics:

Voltage: 125V~
Current: 15A
Total charging capacity 3,1 A

- Climatic characteristics:

Storage temperature: - 10° C to + 70° C
Use temperature: - 5° C to + 35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC 60884-1
Refer to e catalogue