


# MatixGo

JW4129 - JG4129 - JB4129  
JW4039 - JG4039 - JB4039  
JW4188 - JG4188 - JB4188 - J4188R

## Socket outlets American standard

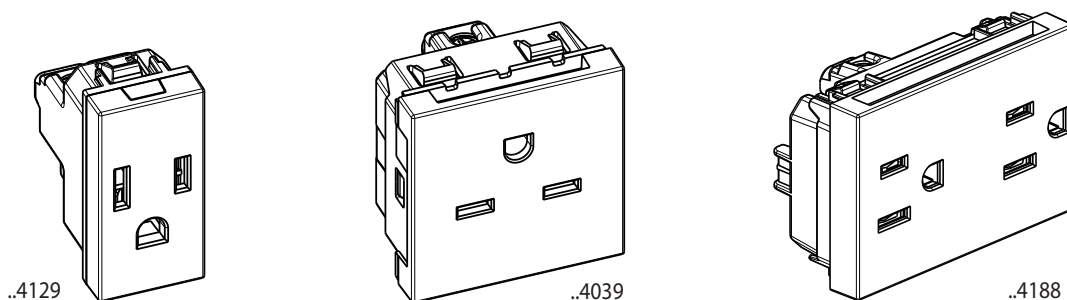

### Use


Socket outlets for: American standard plugs.

### Range

| Designation                                                                                     | Item                                                                                                                                                           |
|-------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Socket American standard 2P+E - 15A<br>- 127/250 V a.c. - shielded tulip contacts<br>- 1 module | <input type="checkbox"/> JW4129<br><input type="checkbox"/> JG4129<br><input checked="" type="checkbox"/> JB4129                                               |
| Socket NEMA 6-15R 15A<br>- 127/250 V a.c. - shielded holes<br>- 2 modules                       | <input type="checkbox"/> JW4039<br><input type="checkbox"/> JG4039<br><input checked="" type="checkbox"/> JB4039                                               |
| Universal Duplex Socket 2P+E - 15A<br>- 127/250 V a.c.<br>- unshielded holes<br>- 3 modules     | <input type="checkbox"/> JW4188<br><input type="checkbox"/> JG4188<br><input checked="" type="checkbox"/> JB4188<br><input checked="" type="checkbox"/> J4188R |

**Colors:** ☐ White ☐ Grey ☒ Black ☒ Red

### Overall dimensions (mm)

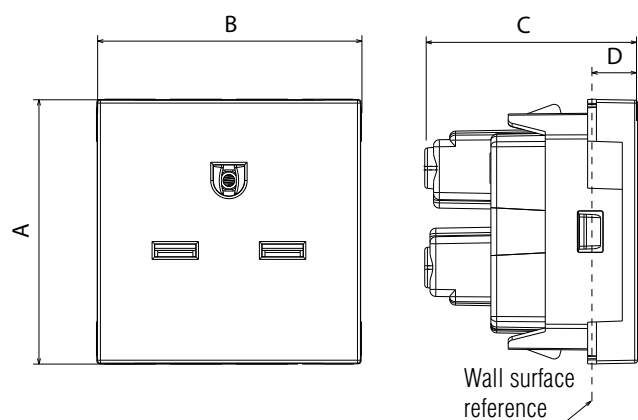

|                  | A    | B    | C    | D   |
|------------------|------|------|------|-----|
| 1 module ..4129  | 45.1 | 22.5 | 35.3 | 7.6 |
| 2 modules ..4039 | 45.1 | 45   | 36.2 | 7.6 |
| 3 modules ..4188 | 45.1 | 67.5 | 34.5 | 7.6 |

### Connection

Terminal type: screw clamp  
Terminal capacity: 2 x 4mm<sup>2</sup> max  
Stripping length: 11 mm  
Compatible with flexibe or rigid cables

### Technical characteristics

- **Protection index:**  
(considering a complete installation, including cover plate)
  - Penetration by solid bodies/liquid: IP21D
  - Impact test: IK04
- **Material characteristics:**
  - Case: PC (polycarbonate)
  - Key cover: PC
  - Halogen Free
  - UV resistant
  - Self-extinguishing:  
850°C/30s for insulating parts holding live parts in place.  
650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
  - Voltage: 127/250 V a.c.
  - Current: 15A
- **Climatic characteristics:**
  - Storage temperature: -10° C a +70° C
  - Use temperature: -5° C a +35° C

### Cleaning

Clean the surface with a cloth.  
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

**Caution: Always test before using special cleaning products.**

### Standards and approvals

Compliance with standards IEC 60884-1.

Refer to e.catalogue.