


MatixGo

Cover plates

Item: refer to the table

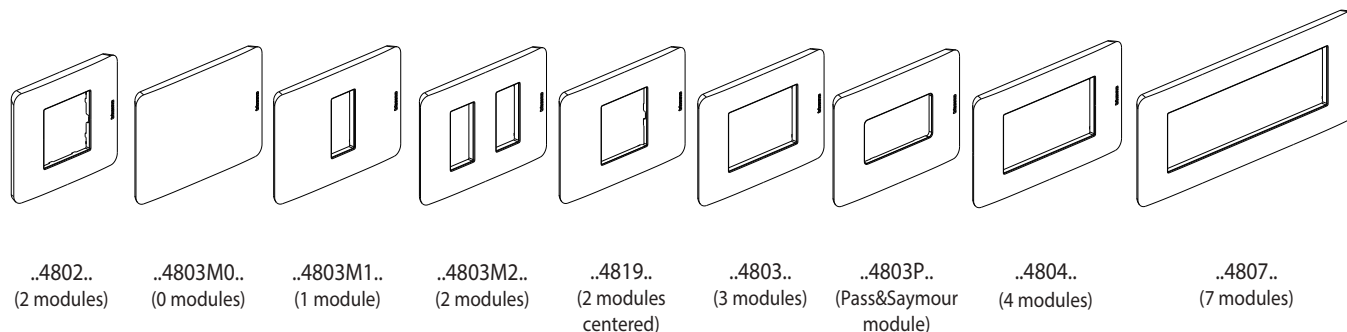


Use										
Rectangular cover plates for dressing mechanisms from 2 to 7 modules.										
Range										
MODULES		2	0	1	1 + 1	2 centered	3	Pass&Seymour*	4	7
MONOCHROME										
	White	JA4802JW	JA4803M0JW	JA4803M1JW	JA4803M2JW	JA4819JW	JA4803JW	JA4803PJW	JA4804JW	JA4807JW
	Grey	JA4802JG	JA4803M0JG	JA4803M1JG	JA4803M2JG	JA4819JG	JA4803JG	JA4803PJG	JA4804JG	JA4807JG
	Black	JA4802JB	JA4803M0JB	JA4803M1JB	JA4803M2JB	JA4819JB	JA4803JB	JA4803PJB	JA4804JB	JA4807JB
TONES										
	Ivory	JA4802TI	JA4803M0TI	JA4803M1TI	JA4803M2TI	JA4819TI	JA4803TI	JA4803PTI	JA4804TI	JA4807TI
	Ritual	JA4802TR	JA4803M0TR	JA4803M1TR	JA4803M2TR	JA4819TR	JA4803TR	JA4803PTR	JA4804TR	JA4807TR
	Sand	JA4802TS	JA4803M0TS	JA4803M1TS	JA4803M2TS	JA4819TS	JA4803TS	JA4803PTS	JA4804TS	JA4807TS
	Agave	JA4802TA	JA4803M0TA	JA4803M1TA	JA4803M2TA	JA4819TA	JA4803TA	JA4803PTA	JA4804TA	JA4807TA
	Tortora	JA4802TD	JA4803M0TD	JA4803M1TD	JA4803M2TD	JA4819TD	JA4803TD	JA4803PTD	JA4804TD	JA4807TD
	Blue	JA4802TB	JA4803M0TB	JA4803M1TB	JA4803M2TB	JA4819TB	JA4803TB	JA4803PTB	JA4804TB	JA4807TB
	Coffee	JA4802TC	JA4803M0TC	JA4803M1TC	JA4803M2TC	JA4819TC	JA4803TC	JA4803PTC	JA4804TC	JA4807TC
EFFECTS										
	Carrara	JA4802EM				JA4819EM	JA4803EM		JA4804EM	JA4807EM
	Aluminum	JA4802EA				JA4819EA	JA4803EA		JA4804EA	JA4807EA
	Steel	JA4802ES				JA4819ES	JA4803ES		JA4804ES	JA4807ES
	Black Nickel	JA4802EN				JA4819EN	JA4803EN		JA4804EN	JA4807EN
ALUMINUM										
	Aluminum		JA4803M0AA	JA4803M1AA	JA4803M2AA	JA4819AA	JA4803AA	JA4803PAA		
	Pearl		JA4803M0AP	JA4803M1AP	JA4803M2AP	JA4819AP	JA4803AP	JA4803PAP		
	Steel		JA4803M0AT	JA4803M1AT	JA4803M2AT	JA4819AT	JA4803AT	JA4803PAT		
BIO										
	Bio					JA4819BB	JA4803BB		JA4804BB	JA4807BB
SPECIALS										
	Antibacterial	JA4802JAB					JA4803JAB		JA4804JAB	
	Red					JA4819JR	JA4803JR	JA4803PJR	JA4804JR	
	Orange					JA4819JO	JA4803JO	JA4803PJO	JA4804JO	
SUPPORT FRAMES										
related item:		J4702 (screws) J4702G (clips)	J4703 J4703M3	J4703 J4703M3	J4703 J4703M3	J4703 J4703M3 J4719V	J4703 J4703M3	*	J4704	J4707

*all Pass&Seymour cover plates are sold with a specific support.

Cover plates

Overall dimensions (mm)

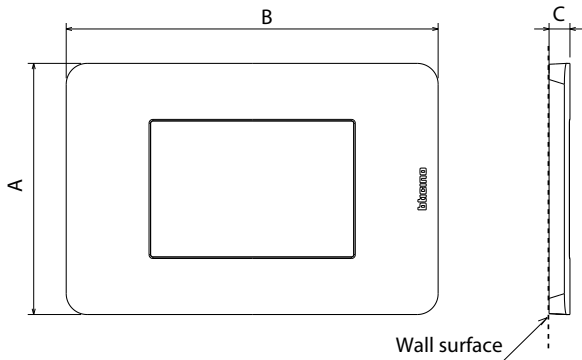

	A	B	C
..4802..	84.2	102.2	7.7
..4819..	84.2	124.7	7
..4803..	84.2	124.7	7
..4804..	84.2	147.2	7
..4807..	84.2	214.7	7

Assembly

The cover plates are fixed to relative supporting frame by clips

Technical characteristics

- **Meccanical test:**
 - Impact test: IK04
- **Material characteristics:**
 - ABS - PHB
 - Halogen Free
 - UV Resistant
 - Self-extinguishing : 650°C -30 sec

650°C-30sec for other insulating part.

- **Climatic characteristic :**
 - Storage temperature : -10° C to +70° C
 - Use temperature : -5° C to +35° C

Cleaning

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN 60669-1

Refer to e.catalogue.