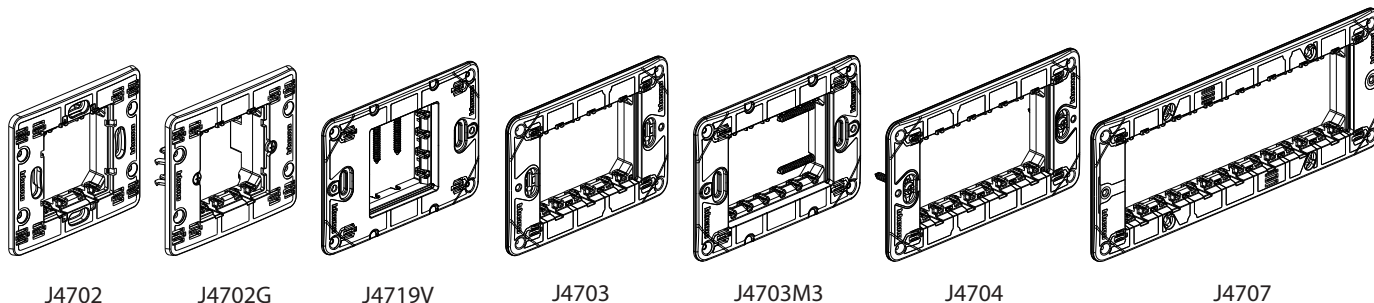


MatixGo

J4702 - J4702G - J4719V - J4703 - J4703M3 - J4704 - J4707

 
 
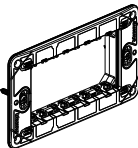
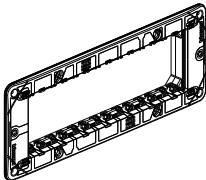
Supporting frames



Use


Supporting frames for mounting Matix GO mechanisms.

Range

Supports for flush-mounting Frame	modules	Item
	2	J4702 J4702G
	2	J4719V
	3	J4703 J4703M3
	4	J4704
	7	J4707

Overall dimensions (mm)

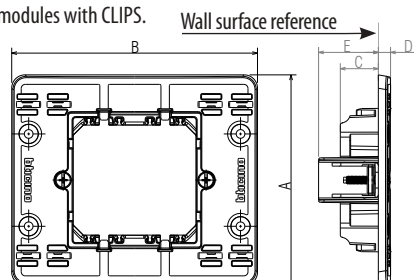
Support frame 2 modules with CLIPS.



Overall dimensions (mm) (continued)

Support frame 2/3/4/7 modules.

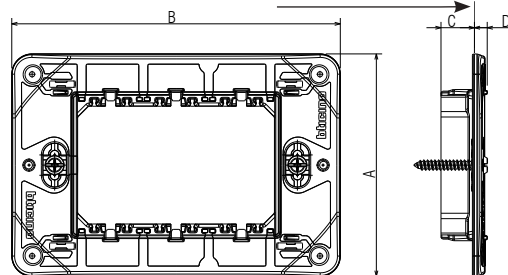Wall surface reference



	A	B	C	D	E
J4702	77.5	90.5	10.5	4.5	22
J4702G	77.5	90.5	10.5	4.5	22
J4719V	76.5	113.5	11.5	4.5	
J4703	76.5	113.5	11.5	4.5	
J4704	76.5	135.5	11.5	4.5	
J4707	76.5	203	11.5	4.5	

Mounting

The supporting frames are screwed to flush mounting boxes.

Technical characteristics

- **Mechanical characteristics** Impact test: IK 04
 - **Material characteristics**
J4702G, J4702 : steel and polyamide glass fiber filled J4719V: ABS
All the other supports polycarbonate Halogen free. UV resistant.
Self-extinguishing: 650° C / 30 s
- Storage temperature: Climatic characteristics- 10° C to + 70° C
Use temperature:
- 5° C to + 35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene. **Caution:**
Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN 60669-1
Refer to e.catalogue.