


Pushbutton lightable with nameplate

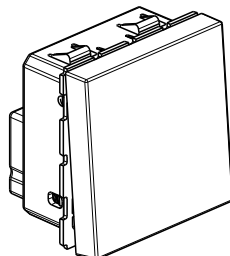


Use

Pushbutton for loads up to 3A

Range

Designation	Item
Pushbutton lightable with nameplate 1P (NO) 3A- 250Va.c. backlighting with integrated white LED (the LED is not interchangeable) 2 modules	J4040

Overall dimensions (mm)

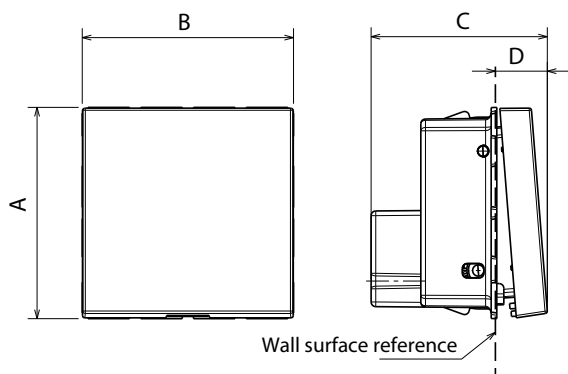

A	B	C	D
45.1	45	37	11

Connection

Terminal type: screw clamp
Terminal capacity: 4 mm max
Stripping length: 11mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: PC
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
850°C/30s for insulating parts holding live parts in place.
650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Voltage: 250 V a.c.
 - Current: 3A
 - Integrated LED: 30Va.c. 0.5W
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN/CEI 60669-1.

Refer to e.catalogue.