


MatixGo

J4373

Flush light indicator

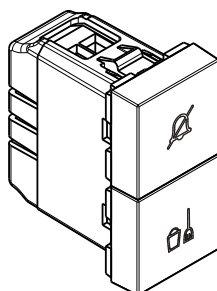

Use

Flush light indicator unit signalling "do not disturb / make up the room", to be used with changeover switch for hotel room. The LEDs are not replaceable.

Range

Designation

Item

Flush light indicator
- power supply 127/230 Va.c.
- 1 module

□ J4373

Colors: □ Opal White


Connection

Terminal type: screw clamp
Terminal capacity: 2 x 1.5 mm² or 1 x 2.5 mm² max
Stripping length: 8 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
- **Material characteristics:**
 - Case / Key cover: PC
 - UV resistant
 - Self-extinguishing:
850°C/30s for insulating parts holding live parts in place.
650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Voltage: 127/230 V a.c.
 - Frequency: 50/60 Hz
 - Power consumption: 2x0.4 W
 - LED light
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Overall dimensions (mm)

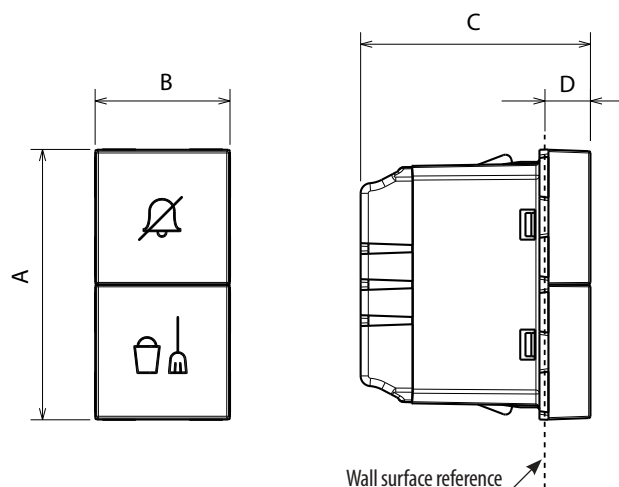

A	B	C	D
45.1	22.5	38.3	7.6

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards CEI/EN62094-1

Refer to e.catalogue.