


MatixGo

J4380

Lighting

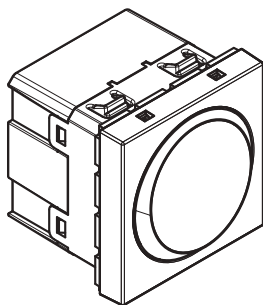

Use


Removable and rechargeable torch with automatic ignition device. It turns on automatically in case of power failure. Push & pull the extraction system (press and pull) complete with recharging base. White light LEDs with high luminous efficiency.

Range

Designation	Item
Removable led lamp. 2 modules	☐ JW4380

Colors: ☐ Opal White

Overall dimensions (mm)

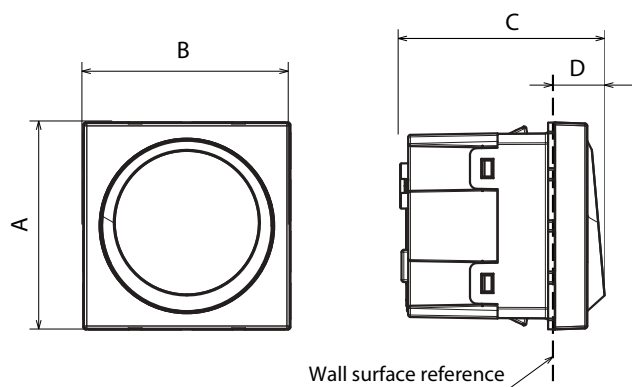

A	B	C	D
45.1	45	44.6	12.7

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 1.5mm² max
Stripping length: 8 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Cover: ABS
 - Light diffuser: PC
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
 - 850°C/30s for insulating parts holding live parts in place.
 - 650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Voltage: 230 V a.c.
 - Frequency: 50/60 Hz
 - Battery NI-MH: - 3.6 V - 80 mA - charging time: 48 h
 - Stand-by consumption at 230 V: 0.2 W - 8.6 mA
 - Stand-by consumption at 110 V: 0.4 W - 13.3 mA
 - Luminous flux: Mode ON: 5 lm - Mode SPOT: 19 lm
 - LED light
 - Autonomy of 2 hours
- **Climatic characteristics:**
 - Storage temperature: -10° C to +70° C
 - Use temperature: -5° C to +35° C

Replacement parts

BT-4380NB: Replacement battery

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals


Compliance with standards:
EN60598-1 / EN60598-2-2 / EN60825-1 EN61547 / EN61000-3-2
EN61000-3-3 / EN55015

Refer to e.catalogue.

Lighting

Photoelectric characteristics

Modo ON

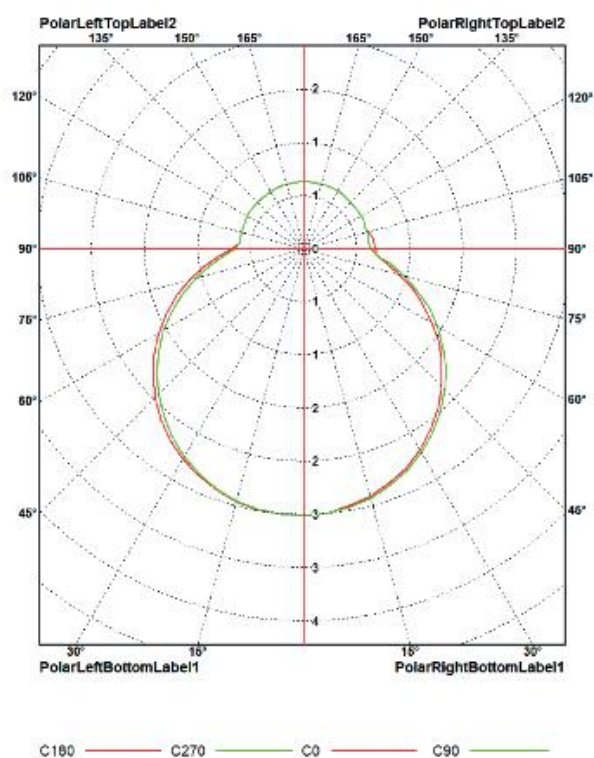

Modo SPOT

