


BULKHEAD LIGHT INDICATOR UNIT

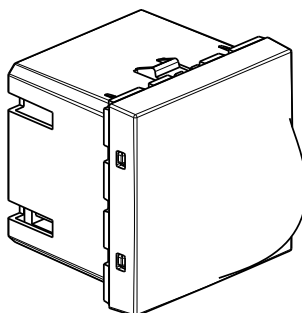

Use

Bulkhead light indicator unit, customizable in different colors connecting the right terminal.


Range

Designation	Item
Bulkhead light indicator unit	■ J4387V230
	■ J4387V12

Color code:

■ Opalescent colour

Overall dimensions (mm)

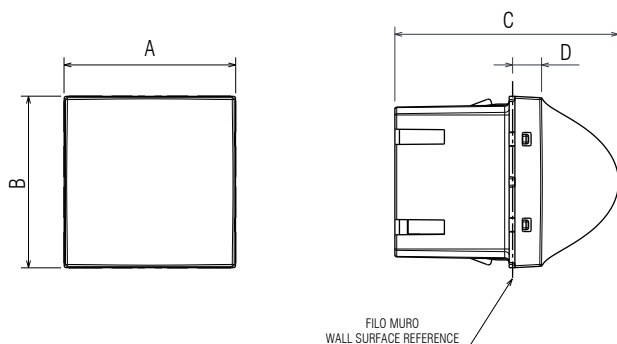


	A	B	C	D
J4387V..	45.1	45.1	58.7	7.6

Connection

Terminal type: screw clamp
 Terminal capacity: 5 x 1,5 mm² max
 Stripping length: 8 mm
 Screwdriver: flat 3
 Compatible with flexible or rigid cables

Connection

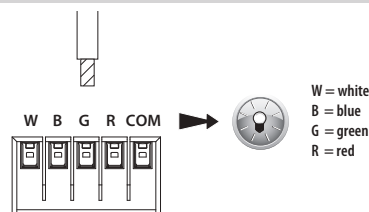

Technical characteristics

- Protection index

(considering a complete installation, including cover plate)
 Penetration by solid bodies/liquid: IP40

- Mechanical characteristics

Impact test: IK 04

- Material characteristics

Material:
 Case and Key cover: PC (Polycarbonate)

Halogen free.

UV resistant.

Self-extinguishing:

850° C / 30 s for insulating parts holding live parts in place
 650° C / 30 s for other parts made of insulating materials

- Electrical characteristics Voltage:

J4387V230 - 127/230V a.c.

J4387V12 - 12/24V a.c./c.c.

Power consumption : 4 x 1.6W

- Climatic characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 35° C

Cleaning

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC 62094-1 (2002-10)

Refer to e.catalogue.