


MatixGo

JW4002 - JW4002AB- JG4002 - JB4002

2P Switches

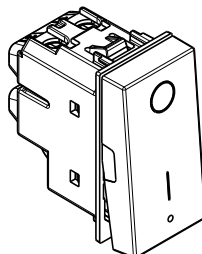

Use

Rocker control device for lighting and other loads.


Range

Designation	Item
One-way 2P 16A - 250Va.c. lightable with led lamp (see table below) 1 module	☐ JW4002 - JW4002AB ☐ JG4002 ☒ JB4002

LED Color	230 Va.c.	12/24 Va.c.	127 Va.c.
White	LN4743/230T	LN4743/12T	LN4743/127T
Blue	H4743/230B	H4743/12B	H4743/127B

Colors: ☐ White ☐ Grey ☒ Black

Overall dimensions (mm)

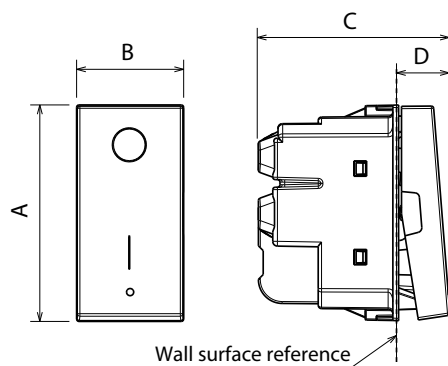

	A	B	C	D
..4002	45.1	22.5	40	11

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 4 mm² max
Stripping length: 9 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: ABS
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
850°C/30s for insulating parts holding live parts in place.
650°C/30s for other parts made of insulating material.
 - The key cover of the JW4002AB items is in antibacterial ABS
- **Electrical characteristics:**
 - Voltage: 250 V a.c.
 - Current: 16A
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN 60669-1.
Refer to e.catalogue.