



MatixGo

JW4027N - JG4027N - JB4027N
JW4037N - JW4037NAB - JG4037N - JB4037N
JW4029 - JG4029 - JB4029

Double interlocked pushbutton and changeover switches

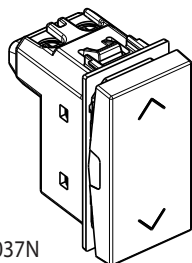

..4027N / ..4037N

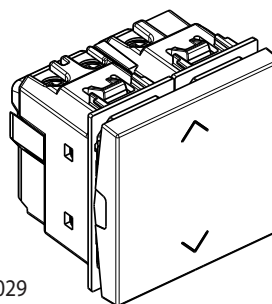

..4029

Use

Control devices for lighting and other loads.


Range

Designation	Item
Changeover switches 1P 10AX - 250Va.c. Key cover 1-0-2 1 module	☐ JW4027N ☒ JG4027N ☒ JB4027N
Double pushbutton with interlock 1P (NO) + 1P (NO) 10A - 250Va.c. 1 module	☐ JW4037N - JW4037NAB ☒ JG4037N ☒ JB4037N
Changeover switches 1P 10AX - 250Va.c. Double Key cover 1-0-2 2 modules	☐ JW4029 ☒ JG4029 ☒ JB4029


Colors: ☐ White ☒ Grey ☒ Black

Overall dimensions (mm)

..4027N / ..4037N

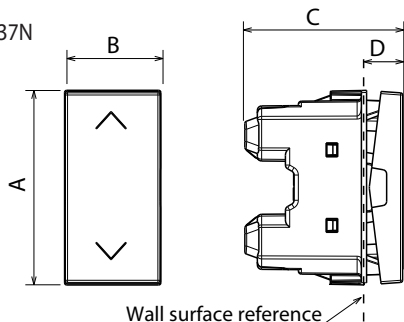

..4029

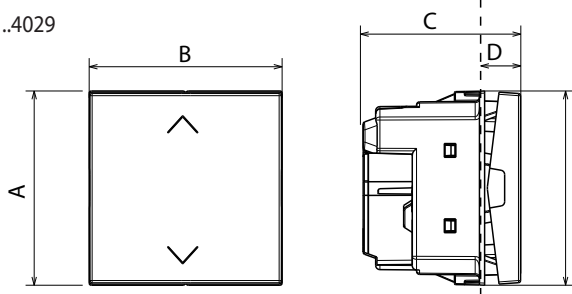

	A	B	C	D
..4027N / ..4037N	45.1	22.5	36.5	8.7
..4029	45.1	45	36.5	8.7

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 4 mm² max
Stripping length: 9 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
 - **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: ABS
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
- 850°C/30s for insulating parts holding live parts in place.
650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Voltage: 250 V a.c.
 - Current: 10AX for ..4027N / ..4029
 - Current: 10A for ..4037N
 - **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN/CEI 60669-1.
Refer to e.catalogue.