



MatixGo

JW4033 - JG4033 - JB4033
JW4033AB
JW4032AB


Cord pushbutton

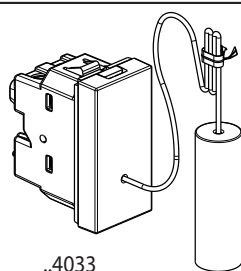

..4033

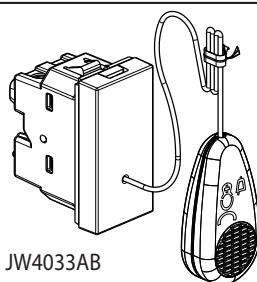

JW4033AB

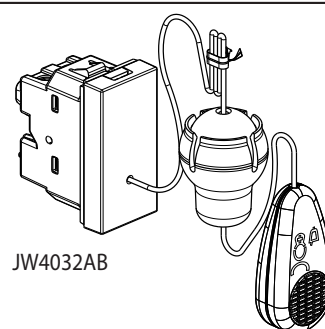

JW4032AB

Use


Cord pushbutton for lighting and other loads.

Range

Designation	Item
Cord pushbutton 1P (NO/NC) 10A - 250Va.c. 1 module	☐ JW4033 - JW4033AB ☒ JG4033 ☒ JB4033
Cord pushbutton anti-tear 1P (NO/NC) 10A - 250Va.c. 1 module	☐ JW4032AB

Colors: ☐ White ☒ Grey ☒ Black

Overall dimensions (mm)

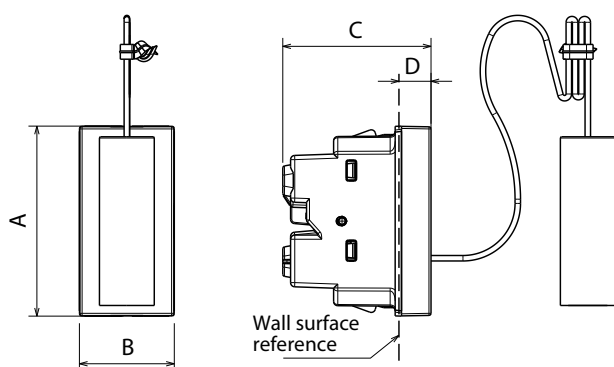

A	B	C	D
45.1	22.5	35.2	7.6

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 4 mm² max
Stripping length: 9 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP40
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: ABS
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
 - 850°C/30s for insulating parts holding live parts in place.
 - 650°C/30s for other parts made of insulating material.
 - The key cover of the following items are in antibacterial ABS
JW4033AB - JW4032AB
- **Electrical characteristics:**
 - Voltage: 250 V a.c.
 - Current: 10A
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN/CEI 60669-1.

Refer to e.catalogue.