



MatixGo

JW4113 - JG4113 - JB4113 - J4113R - J4113O - J4113G
JW4180 - JW4180AB - JG4180 - JB4180 - J4180R - J4180RAB - J4180O - J4180G
JW4140A16 - JW4140A16AB - JG4140A16 - JB4140A16
J4140A16R - J4140A16RAB - J4140A16G - J4140A16O
JW4140A16F - JG4140A16F - JB4140A16F


Socket outlets - Italian Standard

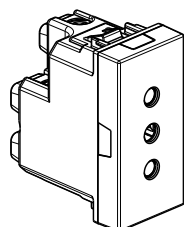


..4113.

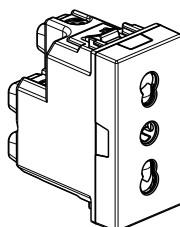

..4180.

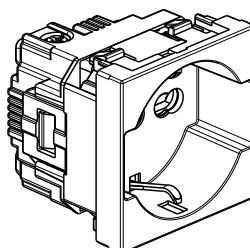

..4140....

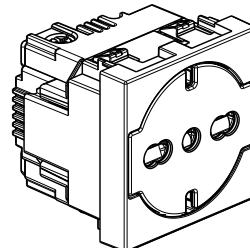

..4140A16F

Use

Socket outlets for: Italian standard, Italian and German standard plugs.


Range

Designation	Item
Socket 2P+T 10A 250V a.c. - centre distance 19 mm shielded tulip contacts Ø4 mm for plug 2P+2P+T 10A Italian standard 1 module	□ JW4113 ■ JG113 ■ JB4113 ■ J4113R ■ J4113O ■ J4113G
Socket 2P+T 10A and 16A 250V a.c. centre distance 19/26 mm - shielded tulip contacts for plug 2P+2P+T 10A and 16A Italian standard 1 module	□ JW4180 - JW4180AB ■ J4180R - J4180RAB ■ JG4180 ■ JB4180 ■ J4180O ■ J4180G
Socket 2P+T 10A and 16A 250V a.c. centre distance 19/26 mm - shielded tulip contacts earth side contacts for German standard plugs suitable for Italian standard plugs 2P and 2P+E 10/16A, German standard plugs 2P+E 16A 2 modules	□ JW4140A16 - JW4140A16AB ■ J4140A16R - J4140A16RAB ■ JG4140A16 ■ JB4140A16 ■ J4140A16O ■ J4140A16G
Socket FLAT 2P+T 10A and 16A 250V a.c. centre distance 19/26 mm - shielded tulip contacts earth side contacts for German standard plugs suitable for Italian standard plugs 2P and 2P+E 10/16A, German standard plugs 2P+E 16A 2 modules	□ JW4140A16 F ■ JG4140A16 F ■ JB4140A16 F

Colors:

☐ White ☐ Grey ☐ Black ☐ Red ☐ Orange ☐ Green

Overall dimensions (mm)

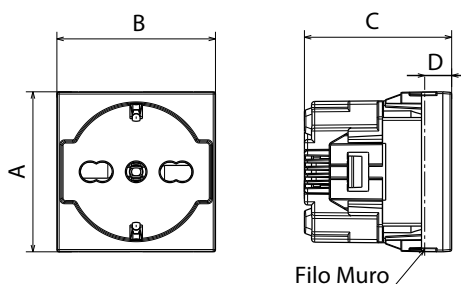

	A	B	C	D
1 module ..4113 / ..4180	45.1	22.3	37.5	7.6
2 modules ..4140....	45.1	44.7	41.5	7.6

Connection

Terminal type: screw clamp
 Terminal capacity: 2 x 4 mm² max
 Stripping length: 11 mm
 Compatible with flexible or rigid cables

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP21D
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: PC (polycarbonate)
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
 - 850°C/30s for insulating parts holding live parts in place.
 - 650°C/30s for other parts made of insulating material.
 - The key cover of the following items are in antibacterial ABS
JW4180AB - J4180RAB - JW4140AB - J4140RAB
- **Electrical characteristics:**
 - Voltage: 250 V a.c.
 - Current: 10A or 16A
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards CEI 23-50 / IEC60884-1
 Refer to e.catalogue.