

MatixGo

JW4125 - JG4125 - JB4125


JW4126 - JG4126 - JB4126

JW4185 - JG4185 - JB4185 - J4185R - J4185O


Socket outlets

Euro-American standard


..4125

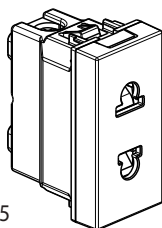

..4126

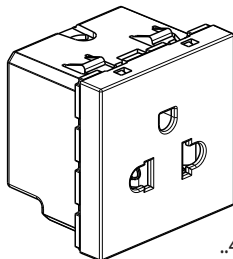

..4185

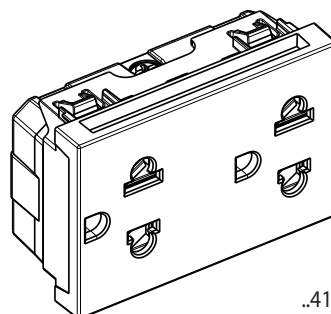

Use


Socket outlets for: Euro-American standard plugs.

Range

Designation	Item
Socket Euro-American standard 2P - 16A - 127/250 Va.c. - shielded tulip contacts - 1 module	☐ JW4125 ☐ JG4125 ☒ JB4125
Socket Euro-American standard 2P+E - 16A - 127/250 Va.c. - shielded tulip contacts - 2 modules	☐ JW4126 ☐ JG4126 ☒ JB4126
Duplex Socket 2P+E - 16A - 127/250 Va.c. - shielded holes - in dual-centre configuration - 3 modules	☐ JW4185 ☐ JG4185 ☒ JB4185 ☒ J4185R ☒ J4185O

Colors: ☐ White ☐ Grey ☒ Black ☒ Red ☒ Orange

Overall dimensions (mm)

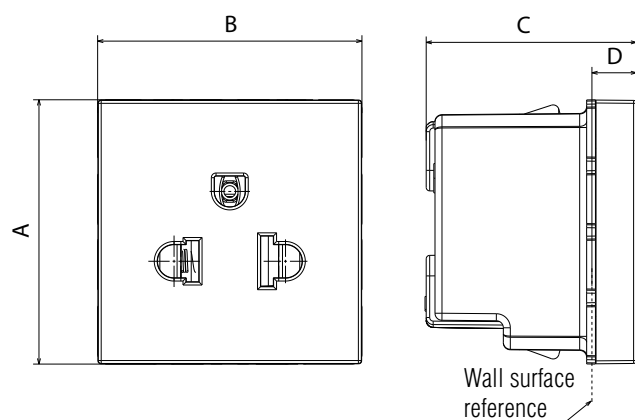

	A	B	C	D
1 module ..4125	45.1	22.5	35.2	7.6
2 modules ..4126	45.1	45	36	7.6
3 modules ..4185	45.1	67.5	34.2	7.6

Connection

Terminal type: screw clamp

Terminal capacity: 2 x 4mm² max

Stripping length: 11 mm

Compatible with flexibe or rigid cables

Technical characteristics

- Protection index:

(considering a complete installation, including cover plate)

- Penetration by solid bodies/liquid: IP21D
- Impact test: IK04

- Material characteristics:

- Case: PC (polycarbonate)
- Key cover: PC
- Halogen Free
- UV resistant
- Self-extinguishing:
850°C/30s for insulating parts holding live parts in place.
650°C/30s for other parts made of insulating material.

- Electrical characteristics:

- Voltage: 127/250 V a.c.
- Current: 16A

- Climatic characteristics:

- Storage temperature: -10° C a +70° C
- Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC 60884-1.

Refer to e.catalogue.