


MatixGo

JW4139 - JG4139 - JB4139

Socket outlets Multistandard

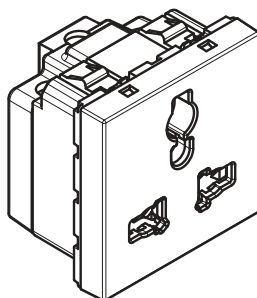

Use

Socket outlets for: Multistandard plugs.

Range

Designation


Item

Socket Multistandard 2P+E - 5/6/10/13A
 - 127/250 Va.c.
 - 5A and 13A = BS std.
 - 6A = indian std.
 - 10A = European std.
 - 2 modules

□ JW4139
 ■ JG4139
 ■ JB4139

Colors: □ White ■ Grey ■ Black

Overall dimensions (mm)

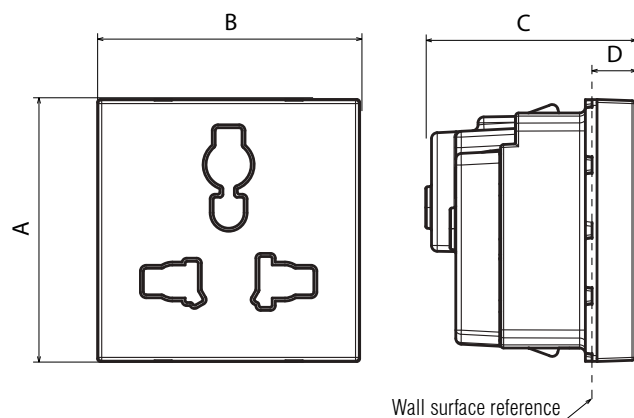

A	B	C	D
45.1	22.5	36	7.6

Connection

Terminal type: screw clamp
 Terminal capacity: 2 x 4mm² max
 Stripping length: 11 mm
 Compatible with flexibe or rigid cables

Technical characteristics

- **Protection index:**
 (considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP21D
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: PC
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
 850°C/30s for insulating parts holding live parts in place.
 650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Voltage: 127/250 V a.c.
 - Current: 5/6/10/13A
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC 60884-1.

Refer to e.catalogue.