


MatixGo

JW4177 - JG4177 - JB4177 - JW4177AB

Shaver sockets

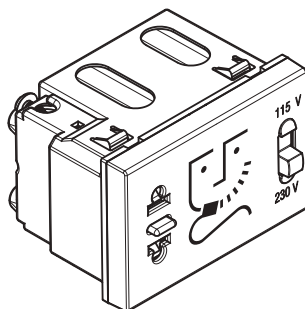

Use

Shaver socket 2P, protected against overloads and direct short-circuits.
Suitable for use with European et American 2-pin plugs.
The mechanism is supplied with rocker plate, to be equipped with support frame and plate.

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 2.5mm² max
Stripping length: 11 mm
Compatible with flexible or rigid cables

Range

Designation	Item
Shaver sockets.	□ JW4177 - JW4177AB
- 3 modules	■ JG4177
	■ JB4177

Colors: □ White ■ Grey ■ Black

Technical characteristics

- **Protection index:**
(considering a complete installation, including cover plate)
 - Penetration by solid bodies/liquid: IP21D
 - Impact test: IK04
- **Material characteristics:**
 - Case: PC (polycarbonate)
 - Key cover: PC for JW4177AB PC antibacterial
 - Halogen Free
 - UV resistant
 - Self-extinguishing:
 - 850°C/30s for insulating parts holding live parts in place.
 - 650°C/30s for other parts made of insulating material.
- **Electrical characteristics:**
 - Nominal input voltage: 230 V a.c.
 - Nominal input frequency: 50 – 60 Hz
 - Nominal output voltage: 115/230 Vac
 - Maximum output current: 20 VA
- **Climatic characteristics:**
 - Storage temperature: -10° C a +70° C
 - Use temperature: -5° C a +35° C

Cleaning


Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN 61558-2-5.

Refer to e.catalogue.

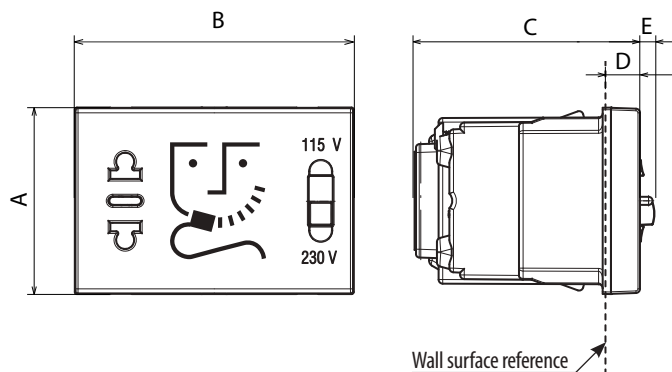

A	B	C	D	E
45.1	67.5	54	7.6	3.5