




On-Q
12-inch Enclosure with Screw-On Cover
Part No. EN1200

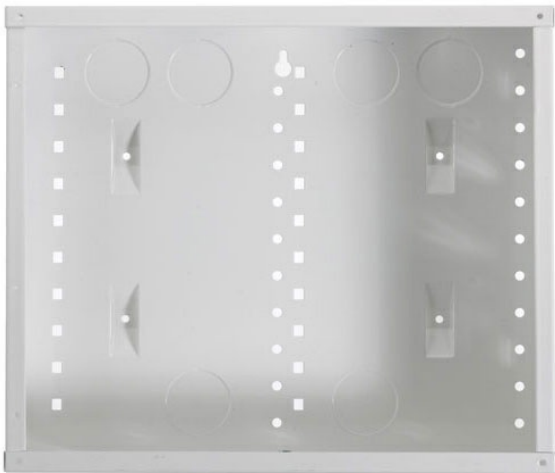

This 12-inch enclosure is the perfect solution for a basic or entry-level structured wiring system. It features large top openings that make pulling wire easier than ever before. The enclosure also boasts multiple knockouts, side lances, and side tabs

Features & Benefits

12-in Enclosure with Screw-On Cover	Drywall depth indicators
Flush and surface installation	Mounting tabs provide correct flush-mount position for standard installations
Patented mounting system offers versatile module mounting options	Literature pouch included for dealer information
Includes self-adhesive cable identification table	Cover included
Made in the USA :	

Specifications

General Info

Product Line	On-Q	Color	White
UPC Number	804428050650	Country Of Origin	United States
Application Sector	Residential	Standard	UL (UL985, UL1023, UL1863), cULus, CSA, RoHS
Type	Enclosure		

Dimensions

Product Width US	14.25 in	Product Depth US	3.6 in
Product Height US	12.13 in		

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	cULus Listed	Yes
------------	-----	--------------	-----

Additional Information

RoHS Compliant	Yes
----------------	-----

Technical Information

Thickness	0.1 in	Cable Entry	(3) top knockouts
-----------	--------	-------------	-------------------

Frame	Cold Rolled Steel
-------	-------------------
