




On-Q  
42-inch Enclosure with Screw-On Cover  
Part No. EN4200

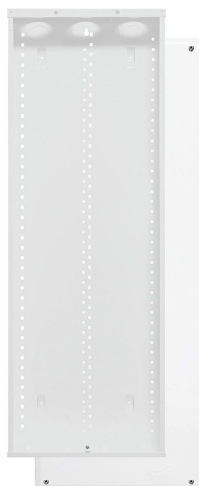

Perfect for larger installations, this 42"" enclosure features universal On-Q style mounting holes that are compatible with all bay-style modules. It also includes larger top openings that make pulling wire easier as well as additional knockouts, more s

## Features & Benefits

|                                                                   |                                                                               |
|-------------------------------------------------------------------|-------------------------------------------------------------------------------|
| 42-in Enclosure with Screw-On Cover                               | Drywall depth indicators                                                      |
| Flush and surface installation                                    | Mounting tabs provide correct flush-mount position for standard installations |
| Patented mounting system offers versatile module mounting options | Literature pouch included for dealer information                              |
| Includes self-adhesive cable identification table                 | Cover included                                                                |
| Made in the USA                                                   |                                                                               |

## Specifications

### General Info

|                    |              |                   |                                              |
|--------------------|--------------|-------------------|----------------------------------------------|
| Product Line       | On-Q         | Color             | White                                        |
| UPC Number         | 804428023166 | Country Of Origin | United States                                |
| Application Sector | Residential  | Standard          | UL (UL985, UL1023, UL1863), cULus, CSA, RoHS |
| Type               | Enclosure    |                   |                                              |

### Dimensions

|                   |          |                  |        |
|-------------------|----------|------------------|--------|
| Product Width US  | 14.25 in | Product Depth US | 3.6 in |
| Product Height US | 42.0 in  |                  |        |

Listing Agencies / 3rd Party Agencies

|            |     |              |     |
|------------|-----|--------------|-----|
| CSA Listed | Yes | cULus Listed | Yes |
|------------|-----|--------------|-----|

Additional Information

|                |     |                               |     |
|----------------|-----|-------------------------------|-----|
| RoHS Compliant | Yes | Product Environmental Profile | Yes |
|----------------|-----|-------------------------------|-----|

Technical Information

|           |                   |             |                                                     |
|-----------|-------------------|-------------|-----------------------------------------------------|
| Thickness | 0.1 in            | Cable Entry | (2) rectangular knockouts for 1-gang electrical box |
| Frame     | Cold Rolled Steel |             |                                                     |