




adorne Collection  
Discontinued - adorne® 15A Two-Gang Pop-Out Outlet, Graphite  
Part No. ARPTR152GG2

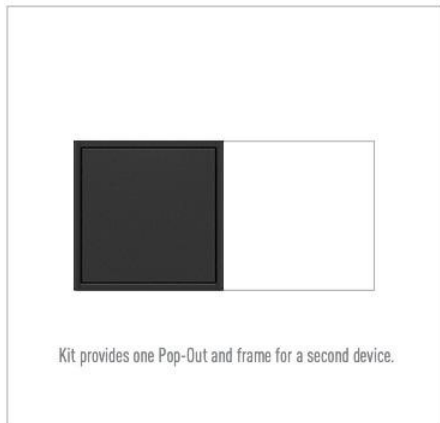

The cleverest way to add power and style, the Pop-Out Outlet extends to offer 3-plug access, then uniquely disappears back into the wall with a simple push when not in use. Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

## Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Provides additional power with 3-plug access when extended from wall.

Installs easily in as little as 15 minutes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

Perfect anywhere you'd like to hide outlets when not in use, for added style and safety.

Disappears back into the wall with a simple push when not needed.

Comes with a special frame for mounting and requires a deep electrical outlet (22.5 cubic inches). No new wires required for typical installation.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

|                       |                           |                    |                                  |
|-----------------------|---------------------------|--------------------|----------------------------------|
| Product Line          | Pass & Seymour            | Color              | Graphite                         |
| UPC Number            | 785007234534              | Country Of Origin  | China                            |
| Number of Receptacles | 3                         | Features           | Pop-Out                          |
| Outlet Type           | Pop-Out, Tamper-Resistant | Application Sector | Multi-Dwelling Unit, Residential |
| Wall Plate Included   | No                        | Warranty Type      | Limited Lifetime Warranty        |

### Dimensions

|                       |             |                          |                                         |
|-----------------------|-------------|--------------------------|-----------------------------------------|
| Product Width US      | 4.8 in      | Product Depth US         | 2.6 in                                  |
| Product Height US     | 4.7 in      |                          |                                         |
| Technical Information |             |                          |                                         |
| Is Tamper-Resistant   | Yes         | Connection Location      | Back Only                               |
| Number of Wires       | 3           | Number of Gangs          | 1                                       |
| Amperage              | 15 A        | Number of Poles          | Double Pole                             |
| Wire Size             | 14 - 12 AWG | Indoor/Outdoor           | Indoor                                  |
| Mounting Type         | Box         | Wire Connection Type     | Internal Pressure Plates                |
| Voltage               | 125.0 V     | Environmental Conditions | 95% (relative humidity, non-condensing) |