




adorne Collection
adorne® 15A Single Tamper-Resistant Outlet, Magnesium
Part No. ARTR151M10

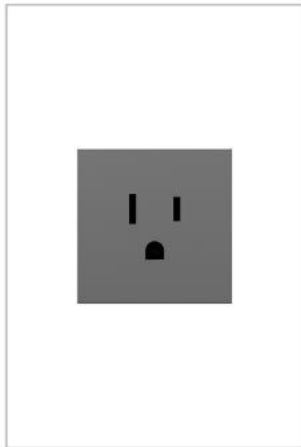

Designed with the same commitment to style and safety as the entire adorne Collection, this device is ideal as a dedicated outlet for large or stationary appliances, or in small or narrow areas where a single plug is needed. The single outlet features "invisi-shutters" for discreet tamper-resistance that keeps children safe without compromising on style.

Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Replaces a standard outlet with ease in as little as 10 minutes.

Creates a designated outlet, ideal for use with appliances or products and devices with larger plugs.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007404340
Country Of Origin	China	Number of Receptacles	1
Features	Pass Through	Outlet Type	Tamper-Resistant
Application Sector	Multi-Dwelling Unit, Residential	Wall Plate Included	No
Standard	RoHS, CSA, cULus, UL, Conforms to NEMA WD-1 and WD-6	Warranty Type	Limited Lifetime Warranty

Dimensions

Product Length US	1.33 in
-------------------	---------

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	cULus Listed	Yes
CSA File Number	C22.2 No.42		

Additional Information

RoHS Compliant	Yes
----------------	-----

Technical Information

Seismic Tested	No	Is Tamper-Resistant	Yes
Connection Location	Back Only	Number of Wires	3
Number of Gangs	1	Amperage	15 A
Number of Poles	Double Pole	Wire Size	14 - 12 AWG
Indoor/Outdoor	Indoor	Wattage	1875 W
NEMA Configuration Code	5-15R	Mounting Type	Box
Wire Connection Type	Internal Pressure Plates	Voltage	125.0 V
Environmental Conditions	Flammability Rating: UL 94 V2		