




adorne Collection
adorne® 15A Dual Tamper-Resistant Plus-Size Outlet, Graphite
Part No. ARTR153G4

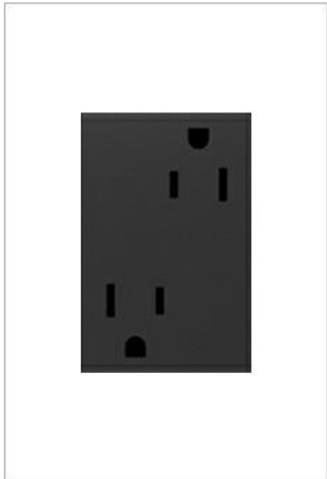

A modern upgrade for style and safety, this tamper-resistant designer outlet from the adorne Collection installs easily for the basic power every home needs, while elevating your space. Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

Features & Benefits

- For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.
 - Replaces any standard outlet with ease, in as little as 10 minutes.
- Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisible shutters" for an invisible effect.
 - More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Graphite
UPC Number	785007234596	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Straight Blade, Tamper-Resistant
Application Sector	Multi-Dwelling Unit, Residential	Wall Plate Included	No
Warranty Type	Limited Lifetime Warranty		

Dimensions

Product Width US	1.77 in	Product Depth US	1.48 in
Product Height US	3.0 in		

Technical Information

Is Tamper-Resistant	Yes	Connection Location	Back Only
Number of Wires	3	Number of Gangs	1
Amperage	15 A	Number of Poles	Double Pole
Wire Size	14 - 12 AWG	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-15R	Mounting Type	Box
Wire Connection Type	Internal Pressure Plates	Voltage	125.0 V
Environmental Conditions	95% (relative humidity, non-condensing)		