


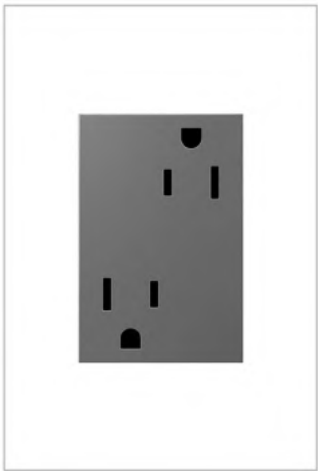

A modern upgrade for style and safety, this tamper-resistant designer outlet from the adorne Collection installs easily for the basic power every home needs, while elevating your space. Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

### Features & Benefits

- For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.
- Replaces any standard outlet with ease, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

### Specifications

#### General Info

|                     |                                  |                       |                                  |
|---------------------|----------------------------------|-----------------------|----------------------------------|
| Product Line        | Pass & Seymour                   | Color                 | Magnesium                        |
| Finish              | Frosted                          | UPC Number            | 785007022810                     |
| Country Of Origin   | China                            | Number of Receptacles | 2                                |
| Outlet Type         | Straight Blade, Tamper-Resistant | Application Sector    | Multi-Dwelling Unit, Residential |
| Wall Plate Included | No                               | Standard              | CULUS                            |
| Warranty Type       | Limited Lifetime Warranty        |                       |                                  |

#### Dimensions

|                   |         |                  |         |
|-------------------|---------|------------------|---------|
| Product Width US  | 1.77 in | Product Depth US | 1.48 in |
| Product Height US | 3.0 in  |                  |         |

Technical Information

|                     |             |                          |                                         |
|---------------------|-------------|--------------------------|-----------------------------------------|
| Is Tamper-Resistant | Yes         | Connection Location      | Back Only                               |
| Phase               | Single      | Number of Wires          | 3                                       |
| Number of Gangs     | 1           | Amperage                 | 15 A                                    |
| Number of Poles     | Double Pole | Wire Size                | 14 - 12 AWG                             |
| Indoor/Outdoor      | Indoor      | NEMA Configuration Code  | 5-15R                                   |
| Mounting Type       | Box         | Wire Connection Type     | Internal Pressure Plates                |
| Voltage             | 125.0 V     | Environmental Conditions | 95% (relative humidity, non-condensing) |