




adorne Collection
adorne® 15W USB Outlet, Type A/C, 20A, Tamper-Resistant, Plus-Size, Magnesium
Part No. ARTRUSB206ACM4

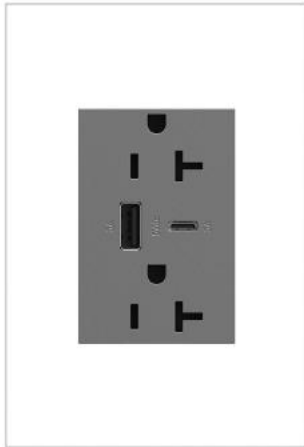

Charge phones, tablets and more up to 40% faster, with USB Outlets from the adorne® Collection. Made to deliver a leading 6 amps of power, it features two built-in USB connections, including one to fit USB Type-C devices, and provides a fast, future-proof solution for convenient in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate(not included). Available in a range of contemporary colors and stunning finishes.

Provides fast and convenient built-in charging, without sacrificing plugs or requiring a bulky adapter.

Features an industry-leading 6.0A of power, as well as Smart Chip technology, to maximize charging speed for each USB connection.

Includes connections for both traditional USB Type-A and the newer USB Type-C , to accommodate all mobile devices.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

Replaces a traditional outlet easily, in as little as 10 minutes. Offers greater plug capacity to accommodate larger products.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007262490
Country Of Origin	China	Number of Receptacles	2
Features	USB-A Charging, USB-C Charging	Outlet Type	Tamper-Resistant, USB-Charging
Application Sector	Commercial, Multi-Dwelling Unit, Residential	Wall Plate Included	No
Standard	yes	Warranty Type	Limited Lifetime Warranty

Dimensions

Product Width US	2.5 in	Product Depth US	1.77 in
Product Height US	3.0 in		

Technical Information

Is Tamper-Resistant	Yes	Connection Location	Back Only
USB Wattage	15 W	USB Amperage	6 A
Connection	USB Type A/C	Number of USBs	2
Number of Wires	3	Number of Gangs	1
Amperage	20 A	Number of Poles	Double Pole
Wire Size	14 - 12 AWG	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-20R	Mounting Type	Box
Wire Connection Type	Internal Pressure Plates	Voltage	125.0 V
Environmental Conditions	95% (relative humidity, non-condensing)		