




adorne Collection
adorne® 30W Dual USB Outlet Module, Type C, Magnesium
Part No. ARUSB30PDM4

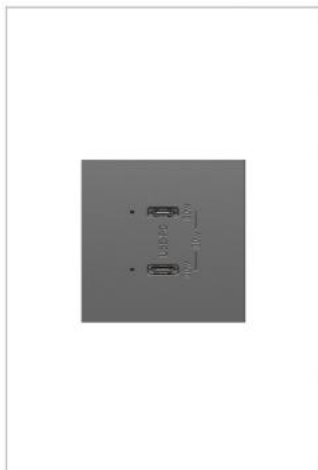

Charge phones, tablets and more up to 40% faster, with USB Outlets from the adorne® Collection. This solution adds advanced Power Delivery to provide fast in-wall charging without an adapter. Easily replacing traditional outlets in as little as ten minutes, this USB Outlet transforms your space with modern functionality and the unique, contemporary aesthetic of adorne. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

For complete installation, device must be paired with an adorne® screwless Wall Plate(not included). Available in a range of contemporary colors and stunning finishes.

Charges the latest devices up to 2X faster with 6.0 amps and 30W of power courtesy of advanced Power Delivery.

Built for intelligent charging, the outlet detects and delivers the precise amount of power needed to maximize charging speeds.

Provides fast and convenient built-in charging through two future-proof USB Type-C ports, accommodating new and upcoming devices without an adapter.

Helpful indicator light lets you see charging status at a glance. Light glows yellow while charging is in progress, and shows green once the device battery is sufficiently charged.

Includes multiple layers of overcurrent protection, ensuring the outlet and your favorite devices can charge at optimal levels without risk of damage.

Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty.

Replaces a traditional outlet easily, in as little as 10 minutes, with features like scalloped cover design and posted side-wire terminal screws for faster installation.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007378047
Country Of Origin	China	Features	Power Delivery, USB-C Charging
Outlet Type	USB-Charging	Application Sector	Commercial, Multi-Dwelling Unit, Residential

Wall Plate Included	No	Warranty Type	Limited Lifetime Warranty
Dimensions			
Product Width US	1.77 in	Product Depth US	1.7 in
Product Height US	2.65 in		
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Connection Location	Back Only	USB Wattage	30 W
USB Amperage	6 A	Connection	USB Type C/C
Number of USBs	2	Number of Wires	3
Output Current	6A	Number of Gangs	1
Amperage	20 A	Number of Poles	Double Pole
Wire Size	14 - 12 AWG	Indoor/Outdoor	Indoor
Mounting Type	Box	Wire Connection Type	Internal Pressure Plates
Environmental Conditions	95% (relative humidity, non-condensing)		