




adorne Collection  
adorne® 20A Paddle Switch, White, with Microban®  
Part No. ASPD2032W4

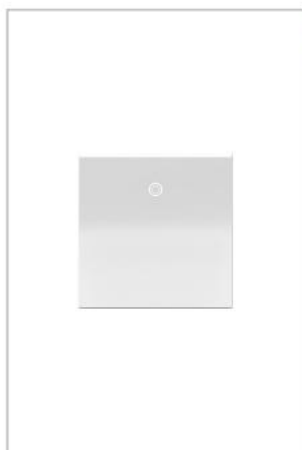

A sleek update to the standard toggle, this modern light switch lets you turn lights on and off with ease and style. Use this 20A light switch on its own to control a light or fixture from a single location, or pair with a second switch for 3-way control.

This switch\* features enduring Microban Registered antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

\* Existing inventory of switches, dimmers and plastic wall plates from the adorne Registered Collection at some partner locations may not yet include Microban Registered protection. To confirm that a specific Legrand product is protected with Microban Registered, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

## Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Installs in 15 minutes or less, fitting into an existing electrical box. No new wiring required for typical installation.

Usable in both single-pole and 3-way applications.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

|                    |                          |                    |                          |
|--------------------|--------------------------|--------------------|--------------------------|
| Product Line       | Pass & Seymour           | Color              | White                    |
| Finish             | Gloss                    | UPC Number         | 785007022759             |
| Country Of Origin  | China                    | Material           | Polycarbonate            |
| Features           | Antimicrobial Protection | Switch Type        | Paddle                   |
| Number of Switches | 1                        | Application Sector | Hospitality, Residential |

|                       |                                                                   |                        |                    |
|-----------------------|-------------------------------------------------------------------|------------------------|--------------------|
| Wall Plate Included   | No                                                                | Standard               | cULus              |
| Warranty Type         | Limited Lifetime Warranty                                         | Type                   | Switch             |
| Dimensions            |                                                                   |                        |                    |
| Product Width US      | 1.77 in                                                           | Product Depth US       | 1.59 in            |
| Product Height US     | 1.77 in                                                           |                        |                    |
| Technical Information |                                                                   |                        |                    |
| Connection Location   | Back Only                                                         | Terminal Accommodation | #14 AWG - #12 AWG  |
| Number of Gangs       | 1                                                                 | Throw Type             | Single Throw       |
| Amperage              | 20 A                                                              | Number of Poles        | 3-Way, Single Pole |
| Requires Neutral Wire | Yes                                                               | Indoor/Outdoor         | Indoor             |
| Mounting Type         | Box                                                               | Location Rating        | Dry                |
| Wire Connection Type  | Internal Pressure Plates                                          | Voltage                | 120.0 V            |
| Load Type             | CFL, Fluorescent, Halogen,<br>Incandescent, LED, Universal, Xenon |                        |                    |