




adorne Collection
adorne® 15A Wave® Switch, Magnesium, with Microban®
Part No. ASWV1532M2

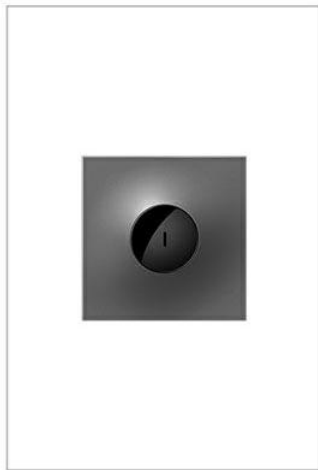

Perfect for turning the lights on or off when your hands are full or messy, especially in entryways or next to the kitchen sink. This touchless, practically hands-free light switch features innovative technology that allows you to control lights with a wave of your hand, for a germ-and-worry free option that also adds contemporary style to any space. Use the sleek, modern switch its own to control a light or fixture from a single location, or pair with a second switch to control a single light source from two locations.

This switch* features enduring Microban Registered antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product.

* Existing inventory of switches, dimmers and plastic wall plates from the adorne Registered Collection at some partner locations may not yet include Microban Registered protection. To confirm that a specific Legrand product is protected with Microban Registered, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label.

Made exclusively for use with screwless Wall Plates from the adorne Registered Collection, sold separately.

No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Features innovative touchless control for a convenient, germ-free way to turn on lights...all it takes is a simple wave.

Includes a rating of up to 1/2 HP for adding touchless control to small motors.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Installs easily in 15 minutes or less, fitting into an existing electrical box. Usable in both single-pole and 3-way applications

Adjust the internal sensor to respond to movement from 1"-6" from the switch face to fit your space and needs.

Specifications

General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Metallic	UPC Number	785007022711

Country Of Origin	China	Material	Polycarbonate
Features	Antimicrobial Protection	Switch Type	Wave
Number of Switches	1	Application Sector	Hospitality, Residential
Wall Plate Included	No	Standard	cULus
Warranty Type	Limited Lifetime Warranty	Type	Switch
Dimensions			
Product Width US	1.77 in	Product Depth US	1.71 in
Product Height US	2.66 in		
Technical Information			
Connection Location	Back Only	Terminal Accommodation	#14 AWG - #12 AWG
Number of Gangs	1	Throw Type	Single Throw
Amperage	15 A	Number of Poles	3-Way, Single Pole
Requires Neutral Wire	Yes	Indoor/Outdoor	Indoor
Mounting Type	Box	Location Rating	Dry
Wire Connection Type	Internal Pressure Plates	Voltage	120.0 V
Load Type	CFL, Fluorescent, Halogen, Incandescent, LED, Universal, Xenon		