




adorne Collection  
adorne® Smart Switch With Netatmo Starter Kit, Magnesium  
Part No. WNAH10KITM1

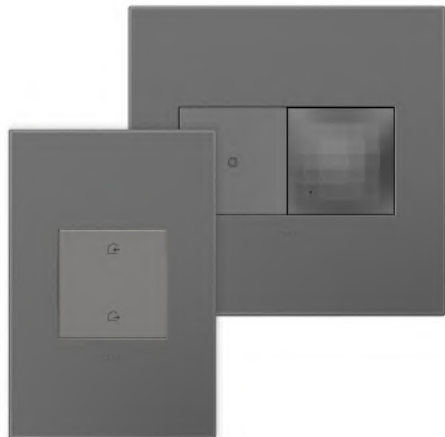

The smartest way to take control of lights and power, optimized for whole home use. Smart Lighting lets you set the exact lighting you need, from anywhere, adding safety and convenience to your home. And delivering it all with unprecedented range and reliability, adorne Registered with Netatmo leverages leading Netatmo technology to provide an ideal solution for larger homes with many smart products. This starter kit comes with a Smart Surface-Mount Gateway to establish the robust and dedicated mesh network, a Smart Switch and a Home/Away Wireless Smart Switch.

## Features & Benefits

The foundation of the adorne with Netatmo solution, the in-wall Gateway easily replaces an existing switch or outlet to provide a discreet hub for a home's smart lighting control.

Ensures ultra-reliable performance through a robust and dedicated mesh-network.

Enables control of a home's smart lighting solutions through the Legrand Home + Control app, allowing for easy scheduling, the creation of groups, setting scenes, managing energy usage and more.

Compatible with other smart products through Amazon Alexa, Google Assistant and Apple HomeKit, as well as with home automation systems.

Part of the adorne with Netatmo solution, which flexibly fits a home's unique needs with a variety of supported smart switches, dimmers and outlets (including other wireless switches and dimmers).

Compatible with all adorne® with Netatmo and radiant® with Netatmo smart devices.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.

## Specifications

### General Info

|                    |                              |             |                                           |
|--------------------|------------------------------|-------------|-------------------------------------------|
| Product Line       | Pass & Seymour               | Color       | Magnesium                                 |
| Finish             | Metallic                     | UPC Number  | 785007380736                              |
| Country Of Origin  | China                        | Material    | Polycarbonate                             |
| Features           | Smart Lighting, With Netatmo | Switch Type | sofTap                                    |
| Number of Switches | 1                            | Works With  | Amazon Alexa, Apple Home Kit, Google Home |

|                                       |                                              |                        |                   |
|---------------------------------------|----------------------------------------------|------------------------|-------------------|
| Application Sector                    | Commercial, Multi-Dwelling Unit, Residential | Wall Plate Included    | No                |
| Warranty Type                         | 2-Year Limited Warranty                      | Type                   | Kit, Switch       |
| Dimensions                            |                                              |                        |                   |
| Product Width US                      | 2.31 in                                      | Product Depth US       | 7.56 in           |
| Product Height US                     | 6.0 in                                       |                        |                   |
| Listing Agencies / 3rd Party Agencies |                                              |                        |                   |
| cULus ListingNumber                   | E350248                                      | cULus Listed           | Yes               |
| FCC Compliant                         | Yes                                          |                        |                   |
| Additional Information                |                                              |                        |                   |
| RoHS Compliant                        | Yes                                          |                        |                   |
| Technical Information                 |                                              |                        |                   |
| Connection Location                   | Back Only                                    | Terminal Accommodation | #14 AWG - #12 AWG |
| Connection                            | Wireless                                     | Amperage               | 15 A              |
| Number of Poles                       | Multi-Location                               | Requires Neutral Wire  | Yes               |
| Indoor/Outdoor                        | Indoor                                       | Location Rating        | Dry               |
| Voltage                               | 120 VAC                                      |                        |                   |