


Lamp holder

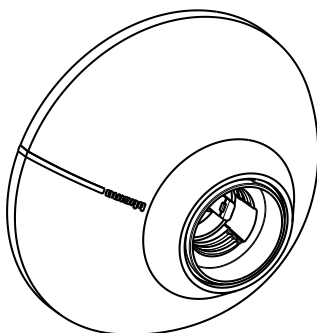

P23..

Use


2 pieces lamp holder for lamp E27, max 100W.
It can be installed on wall boxes, directly on the wall or on the ceiling.

Range

Designation

Item

Lamp holder

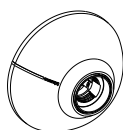


□ P23A
■ P23B

Color code:

□ White

■ Ivory

Overall dimensions (mm)

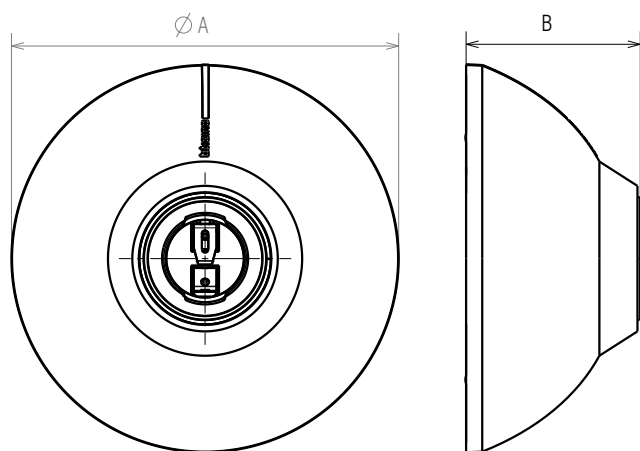

	A	B
P23..	120	54

Connection

Terminal type: automatic clamp
Terminal capacity: 2 x 1.5 mm² max
Stripping length: 10 mm
Compatible with flexible or rigid cables

Technical characteristics

- **Protection index**
(considering a complete installation Penetration by solid bodies/liquid: IP40)
- **Mechanical characteristics**
Impact test: IK 04
- **Material characteristics**
Materials:
 - Covers: PC
 - Internal structure: PBT
- **Electrical characteristics:**
 - Voltage: 127V a.c. - 250 V a.c.
 - Current: 0.4A (230V~) - 0.8A (127V~)
 - Power: 100W Max

UV resistant. Halogen free.

Self-extinguishing:

850° C / 30 s for parts made of insulating materials

- Climatic characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 35° C

Cleaning

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards CEI EN 50598-1

Refer to e.catalogue.