


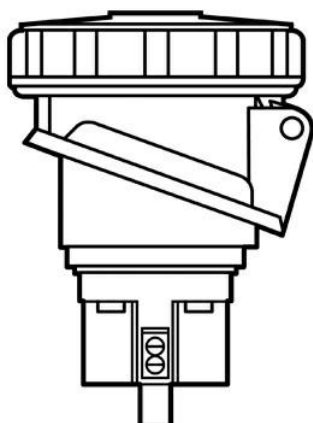

4-Pole, 5-Wire Pin and Sleeve Receptacle, 20A, 3 Phase Y 227/480V

Features & Benefits

Legrand Pin & Sleeve products provide installation ease, enduring performance in harsh conditions, and guaranteed IEC 309 compatibility.

Nylon construction for high impact and corrosion resistance.

Locking ring with an integral neoprene gasket provides watertight seal when plug and connector/receptacle are mated.

Combination-head screws for added convenience and quick installation.

Cover with integral neoprene gasket provides watertight seal.

Arrives ready to wire, with cord grip open and cable-ready. Terminal screws come backed out and ready to wire. Front and back body require no disassembly prior to assembly.

Nickel-plated brass pins provide extra corrosion resistance without sacrificing electrical conductivity.

Natural-rubber grommets provide watertight protection at cable entry.

Revolutionary, hinged cord grip for durable performance and ease of installation.

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007520088	Country Of Origin	United States
Features	Watertight	Application Sector	Industrial
Warranty Type	1-Year	Type	Receptacle

Dimensions

Product Width US	3.4 in	Product Height US	3.8 in
------------------	--------	-------------------	--------

Product Length US	3.7 in
-------------------	--------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	151348	cULus Listed	Yes
---------------------	--------	--------------	-----

Technical Information

Connector Style	Pin & Sleeve	Flanged	No
-----------------	--------------	---------	----

Number of Wires	5	Amperage	20 A
-----------------	---	----------	------

Indoor/Outdoor	Both	Voltage	277/480 VAC
----------------	------	---------	-------------