




**Pass and Seymour**  
**Wood and Steel Stud Bracket Box with Quick/Click**  
Part No. S118S50

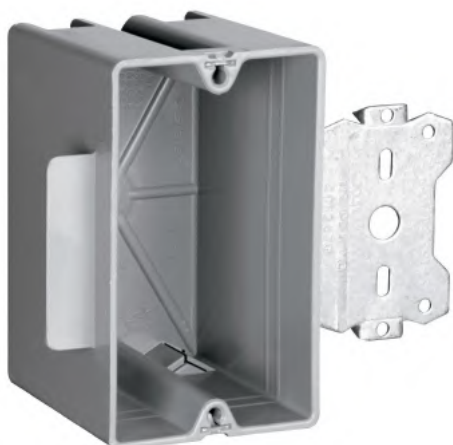

Single gang, wood and steel stud bracket box with 3/8 offset for wood and steel stud mounting. It has two Quick/Click Entries for each end, for use with 3/8 and 5/8 wallboard. It is available in single, two, three, four gang and 4 inch square boxes. It is m

## Features & Benefits

Two, three and four gang boxes and 4 inch square include exclusive Auto/Clamp feature.

Quick/Click feature offers fast and dependable installation of devices (single, two, three, and four gang).

Available with 3/8 inch offsets.

Single gang include Quick/Entry feature.

Unique offset tab assures proper alignment to wall face.

Can be installed on steel studs with most standard crimping tools in addition to CT1 Crimping Tool.

## Specifications

### General Info

|                       |                         |                     |                                        |
|-----------------------|-------------------------|---------------------|----------------------------------------|
| Product Line          | Pass & Seymour          | Color               | Gray                                   |
| UPC Number            | 785007207040            | Country Of Origin   | United States                          |
| Material              | Thermoplastic           | Features            | Quick Entry, Shallow, Steel Stud Mount |
| Installation Location | Wall                    | Number of Knockouts | 4                                      |
| Application Sector    | Commercial, Residential | Standard            | UL Listed                              |
| Warranty Type         | 1-Year Limited Warranty | Type                | Switch & Outlet Boxes                  |

### Dimensions

|                  |         |                   |         |
|------------------|---------|-------------------|---------|
| Product Width US | 2.25 in | Product Weight US | 0.25 lb |
|------------------|---------|-------------------|---------|

|                   |            |                   |          |
|-------------------|------------|-------------------|----------|
| Product Volume US | 18.0 cu in | Product Depth US  | 2.719 in |
| Product Height US | 3.75 in    | Product Length US | 3.75 in  |
| Cubic Capacity    | 18 in³     |                   |          |

Additional Information

|                |     |                               |     |
|----------------|-----|-------------------------------|-----|
| RoHS Compliant | Yes | Product Environmental Profile | Yes |
|----------------|-----|-------------------------------|-----|

Technical Information

|                 |                   |                |             |
|-----------------|-------------------|----------------|-------------|
| Number of Gangs | 1                 | Indoor/Outdoor | Indoor      |
| Cable Entry     | Back, Bottom, Top | Box Shape      | Rectangular |
| Mounting Type   | Stud Mount        |                |             |