




Pass and Seymour
Old Work Switch and Outlet Box with Quick/Click
Part No. S352W

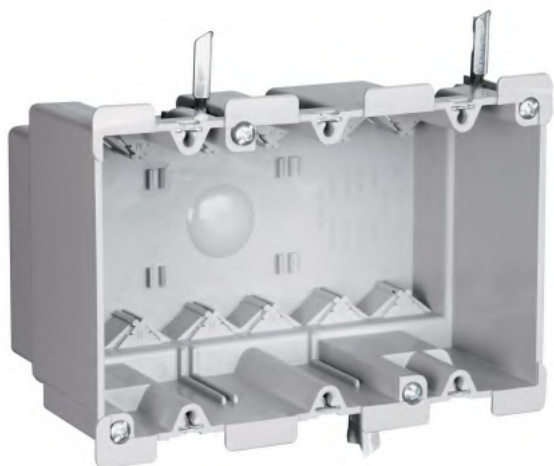

Triple Gang, Old Work Switch and Outlet Box with Swing-Bracket for mounting. Adjusts from 1 1/4-inch down to 1/8-inch. Six Auto/Clamps for Each End. 10 pack.

Features & Benefits

Quick/Click feature secures devices quickly and easily.

Does not strip when over-torqued.

6: Auto/Clamps on each end eliminate the need for separate cable clamps.

Metal swing bracket for quick mounting in existing walls.

Big 52 cubic inch capacity.

Divider plate (LVDIV1, sold separately) used when installing line and low-voltage devices or multiple 277 volt devices in same box.

Easy installation, rectangular cutout.

Swing bracket adjusts from 1 1/4 inch to 1/8 inch.

Durable, impact-resistant thermoplastic box.

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007179149	Country Of Origin	United States
Material	Thermoplastic	Features	Auto Clamps, Old Work, Quick Entry
Application Sector	Commercial, Residential	Standard	UL Listed
Warranty Type	1-Year Limited Warranty	Type	Switch & Outlet Boxes

Dimensions

Product Width US	5.875 in	Product Weight US	0.43 lb
------------------	----------	-------------------	---------

Product Volume US	52.0 cu in	Product Depth US	3.031 in
Product Height US	3.75 in	Product Length US	3.75 in
Cubic Capacity	52 in³		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Number of Gangs	3	Indoor/Outdoor	Indoor
Cable Entry	Back, Bottom, Top	Box Shape	Rectangular
Mounting Type	Swing Bracket		