




Pass and Seymour
2-Gang 430 Stainless Steel Wall Plate, 2 Duplex Receptacle Openings
Part No. SL82

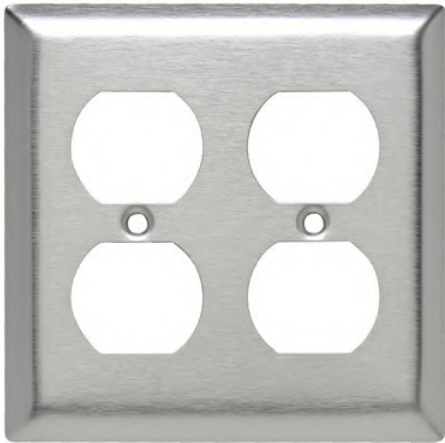

Smooth Metal Wall Plate 1-Gang Duplex 430 Stainless Steel

Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.	Brushed finish.
Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.	Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.
Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.	Packaged in protective film, with finish-matching screws.
Variety of special plated finishes.	Paintable to match plastic plates.
Can be silk-screened or engraved, and custom punched with over 300 opening styles.	For covering patents, see www.legrand.us/patents .

Specifications

General Info

Product Line	Pass & Seymour	Color	Stainless Steel
Finish	Metallic	UPC Number	785007658033
Country Of Origin	United States	Material	Stainless Steel
Wall Plate Size	Standard Size	Wall Plate Type	Duplex Receptacle
Application Sector	Commercial, Residential	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

Dimensions

Product Width US	4.56 in	Product Depth US	0.2 in
Product Height US	4.5 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143223	cULus Listed	Yes
---------------------	--------	--------------	-----

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Thickness	0.032 in	Number of Gangs	2
Indoor/Outdoor	Indoor	Mounting Type	Strap Mounted
Orientation	Vertical		