




Pass and Seymour
1-Gang Thermoset Wall Plate, 0.625-in Round Opening, White
Part No. SP11W

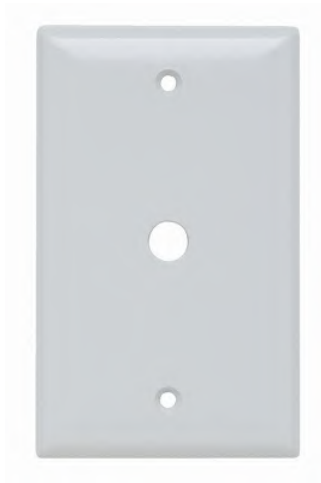

Single-Gang, single telephone or cable outlet 13/32-inch hole. Box mounted. Smooth thermoset. .

Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007680959
Country Of Origin	Mexico	Material	Thermoset Plastic
Construction	Plastic	Wall Plate Size	Standard Size
Wall Plate Type	Outlet, Round	Application Sector	Commercial, Residential
Standard	CSA, UL514	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

Dimensions

Product Width US	2.75 in	Product Depth US	0.2 in
Product Height US	4.5 in	Circular Outlet Diameter	0.625 in
Listing Agencies / 3rd Party Agencies			
CSA Listed	Yes	CSA File Number	143222
Additional Information			
Product Environmental Profile	Yes		
Technical Information			
Thickness	0.07 in	Number of Gangs	1
Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
Orientation	Vertical		