




Pass and Seymour
TradeMaster® 3-Gang Nylon Wall Plate, 3 Decorator Openings, Ivory
Part No. TP263I

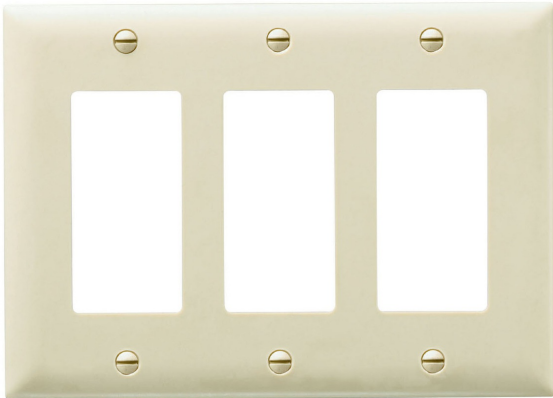

The TradeMaster Registered thermoplastic 3-gang decorator wall plate provides maximum durability in plastic wall plates. Self-extinguishing nylon construction makes these wall plates virtually unbreakable. They are 3/16 of an inch higher and wider than typical plastic wall plates - not enough to be apparent to the eye, but the extra size cuts cost by reducing dry wall rework.

Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

Specifications

General Info

Product Line	Pass & Seymour	Color	Ivory
Finish	Matte	UPC Number	785007275575
Country Of Origin	United States	Material	Nylon
Construction	Plastic	Wall Plate Size	Standard Size
Wall Plate Type	Decorator	Application Sector	Commercial, Residential
Standard	CSA, UL514	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

Dimensions

Product Width US	6.563 in	Product Depth US	0.25 in
Product Height US	4.6875 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	143222	cULus Listed	Yes
Additional Information			
Product Environmental Profile	Yes		
Technical Information			
Thickness	0.07 in	Number of Gangs	3
Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
Orientation	Vertical		