




Wiremold
4000 Radiused Insert for Internal/External Elbow Fitting
Part No. 4017/18RI

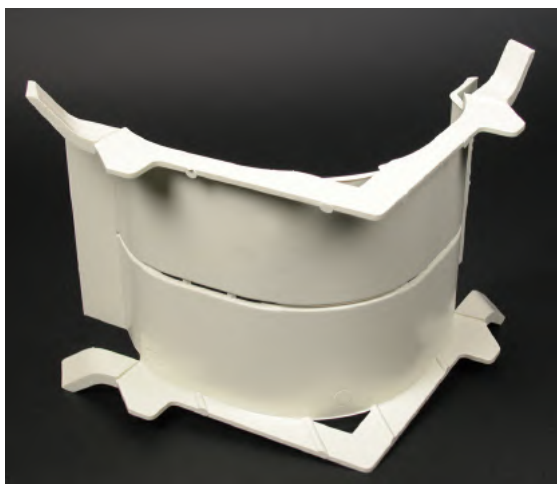

Radiused insert for 4017 Internal Elbow and 4018 External Elbow in divided or undivided applications. Provides 2" (51mm) cable bend radius control for UTP, STP and fiber optic cable installations. Ideal for new and retrofit applications whether the cable installation is lay-in or pull-through.

Features & Benefits

Radiused insert for 4017 Internal Elbow and 4018 External Elbow in divided or undivided applications.

Provides 2" (51mm) cable bend radius control for UTP, STP and fiber optic cable installations. Ideal for new and retrofit applications whether the cable installation is lay-in or pull-through.

Specifications

General Info

Product Line	Wiremold	Color	Silver/White
UPC Number	786776534078	Country Of Origin	United States
Material	Steel	Product Series	4000 Series
Installation Location	On Wall	Application Sector	Commercial
Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Fitting		

Dimensions

Product Width US	6.0 in	Product Weight US	0.55 lb
Product Height US	4.75 in	Product Length US	6.0 in

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Is Pre-Wired	No	Indoor/Outdoor	Indoor
--------------	----	----------------	--------

Voltage	600.0 V
---------	---------
