




Wiremold
861AMDTC Series Wood Floor Box Assembly
Part No. 861AMDTCBK

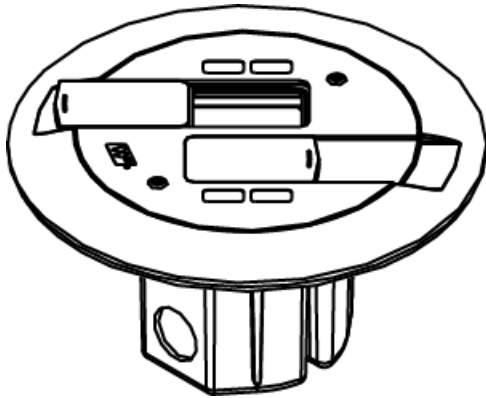

All communication floor boxes accept up to four UTP connectors. Flush poke-thru-style flanges available. Slide covers match painted flange colors. Aluminum and brass flanges shipped with black slide cover. Brass flange also available with nonmetallic brass-color slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu. cm.) capacity. Requires a 4" (102mm) diameter hole and overall floor depth of 1" (25mm). Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters. Assembled with scrub water gasket. For use on tile, wood, or carpet floors. Modular jacks sold separately.

Features & Benefits

All communication floor boxes accept up to four UTP connectors	Flush poke-thru-style flanges available
Slide covers match painted flange colors	Aluminum and brass flanges shipped with black slide cover
Brass flange also available with nonmetallic brass-color slide holder	Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters
Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters	Assembled with scrub water gasket
For use on tile, wood, or carpet floors	Modular jacks sold separately
Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu. cm.) capacity.	For use on tile, wood, or carpet floors

Specifications

General Info

Product Line	Wiremold	Finish	Painted
UPC Number	786564013310	Country Of Origin	Mexico
Material	Die-Cast Aluminum	Construction	Assembled
Cover Style	Flush	Number of Knockouts	3
Cover Material	Die-Cast Aluminum	Application Sector	Commercial

Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Floor Box		
Dimensions			
Product Weight US	2.0 lb	Cubic Capacity	18 in³
Knockout Size	1/2 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E2961	cULus Listed	Yes
Trade Programs			
USMCA	Yes		
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Floor Type	Raised, Wood	Service Capacity	Single
Minimum Floor Depth	1 in	Box Capacity	1 Gang
Cable Entry	Knockout		