




Wiremold
861FFTC Series Furniture Feed Raised Floor Box Assembly
Part No. 861FFTCBK

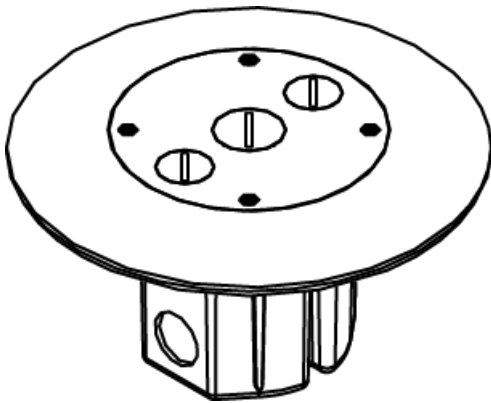

Cover has two 1/2" trade size conduits and one 3/4" trade size threaded conduit opening for feeding cables and wires through the floor. Flush flanges available in a variety of colors/finishes. Slide covers match painted flange colors. Aluminum and brass covers shipped with black slide covers. Brass flange also available with nonmetallic brass-color slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu.cm) capacity. Requires a 4" (102mm) diameter hole.

Features & Benefits

Cover has two 1/2" trade size conduits and one 3/4" trade size threaded conduit opening for feeding cables and wires through the floor.

Flush flanges available in a variety of colors/finishes

Slide covers match painted flange colors

Aluminum and brass covers shipped with black slide covers

Brass flange also available with nonmetallic brass-color slide holder

Specifications

General Info

Product Line	Wiremold	Finish	Painted
UPC Number	786564013402	Country Of Origin	Mexico
Material	Die-Cast Aluminum	Construction	Assembled
Cover Style	Flush, Furniture Feed	Number of Knockouts	3
Cover Material	Die-Cast Aluminum	Application Sector	Commercial
Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Floor Box		

Dimensions

Product Weight US	2.5 lb	Product Depth US	4.0 in
-------------------	--------	------------------	--------

Product Height US	3.78 in	Cubic Capacity	18 in³
Knockout Size	1/2 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E2961	cULus Listed	Yes
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Floor Type	Raised, Wood	Service Capacity	Single
Minimum Floor Depth	1 in	Box Capacity	1 Gang
Cable Entry	Knockout		