




Wiremold
Omnibox® Series Double Gang Shallow Steel Floor Box
Part No. 880M2

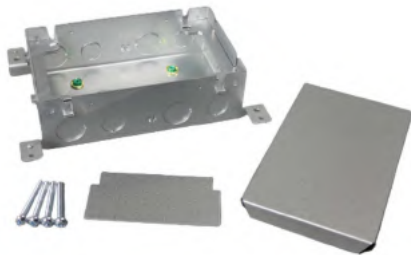

The 880M2 shallow two gang Omnibox® Floor Box provides an excellent activation solution for applications where single service is required in open space areas. The 880M2 floor box is offered in a stamped steel construction, designed to be installed in above grade concrete floor applications and to meet a wide range of market requirements. This floor box series has many applications, some of which are schools, financial institutions, and commercial office buildings.

Features & Benefits

TopGuard protection. All cover assemblies for the Omnibox Floor Box Series have TopGuard protection. An integral design which keeps out water, dirt, and debris from the power and communication compartments.

Concrete-tight stamped steel construction. Lower cost option for above grade applications.

Boxes and covers have been listed by Underwriters Laboratories Inc. to their standard UL514A, 514C, 514D, and Canadian standard C22.2.

Datacom connectivity options. Accepts industry standard and proprietary devices from a wide range of manufacturers to provide a seamless and aesthetically pleasing interface for voice, data, audio, and video applications at the point-of-use.

Fully adjustable box. Before and after concrete pour adjustability. Lower installed cost.

Two-gang configurations, maximum flexibility. Can remove divider for greater capacity. Supports multiservice applications.

Flush activation assemblies for carpet and tile. Aesthetically pleasing assemblies are interchangeable for both cast-iron and stamped steel.

A wide selection of data and bezel options available for use with Ortronics TracJack and Series II devices.

Specifications

General Info

Product Line	Wiremold	Color	Silver
UPC Number	786564221739	Country Of Origin	Mexico
Material	Steel	Construction	Assembled
Cover Style	Flush	Number of Knockouts	2

Application Sector	Commercial, Education	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT. Meets Article 314.27(C) of NEC.
--------------------	-----------------------	----------	---

Warranty Type	1-Year from Installation or 2-Years from Day of Sale	Type	Floor Box
---------------	---	------	-----------

Dimensions

Product Width US	7.0 in	Product Weight US	3.296 lb
------------------	--------	-------------------	----------

Product Volume US	166.25 cu in	Product Depth US	9.5 in
-------------------	--------------	------------------	--------

Product Height US	2.5 in	Cubic Capacity	80 in ³
-------------------	--------	----------------	--------------------

Knockout Size	1/2 in, 3/4 in
---------------	----------------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Floor Type	Concrete	Service Capacity	Dual
------------	----------	------------------	------

Box Capacity	2 Gangs	Cable Entry	Knockout
--------------	---------	-------------	----------

Box Type	Above-Grade	Number of Outlets	0
----------	-------------	-------------------	---

Depth Behind Device Plates	1.75 in
----------------------------	---------