




Wiremold  
AC Series™ AC10105 Eight Gang Raised Floor Box with Gray Carpet style Lid  
Part No. AC10105-2

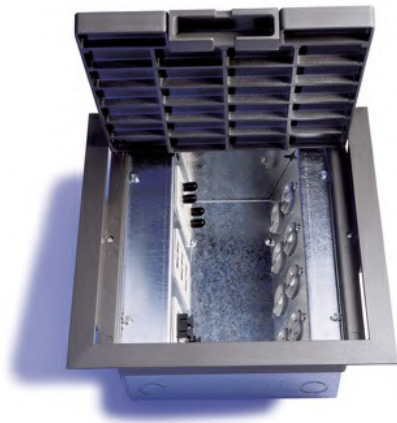

With a 5 inch (127mm) depth, the AC Series™ AC10105 Raised Floor Box provides eight gangs of power and/or communication device capacity. Power plate with duplex knockouts included with box. It also provides increased plug-in volume which is ideal for the additional space needed when plugging in transformer type plugs. Lids can be rotated 180° for easy orientation. Gray lids are die-cast zinc construction, and allow for a carpet or tile insert.

## Features & Benefits

This product meets the material restrictions of RoHS

## Specifications

### General Info

|                     |                                                      |                   |                                                                                           |
|---------------------|------------------------------------------------------|-------------------|-------------------------------------------------------------------------------------------|
| Product Line        | Wiremold                                             | Color             | Gray                                                                                      |
| UPC Number          | 786564018773                                         | Country Of Origin | United States                                                                             |
| Material            | Steel                                                | Construction      | Assembled                                                                                 |
| Number of Knockouts | 2                                                    | Cover Material    | Die-Cast Zinc                                                                             |
| Application Sector  | Commercial                                           | Standard          | cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC. |
| Warranty Type       | 1-Year from Installation or 2-Years from Day of Sale | Type              | Floor Box                                                                                 |

### Dimensions

|                   |              |                   |          |
|-------------------|--------------|-------------------|----------|
| Product Width US  | 11.5 in      | Product Weight US | 17.05 lb |
| Product Volume US | 677.78 cu in | Product Depth US  | 11.5 in  |

|                                       |                |                            |                     |
|---------------------------------------|----------------|----------------------------|---------------------|
| Product Height US                     | 5.13 in        | Cubic Capacity             | 115 in <sup>3</sup> |
| Knockout Size                         | 1/2 in, 3/4 in |                            |                     |
| Listing Agencies / 3rd Party Agencies |                |                            |                     |
| cULus ListingNumber                   | E2961          | cULus Listed               | Yes                 |
| Trade Programs                        |                |                            |                     |
| USMCA                                 | Yes            |                            |                     |
| Additional Information                |                |                            |                     |
| RoHS Compliant                        | Yes            |                            |                     |
| Technical Information                 |                |                            |                     |
| Floor Type                            | Raised         | Service Capacity           | Triple              |
| Minimum Floor Depth                   | 5 in           | Box Capacity               | 8 Gangs             |
| Cable Entry                           | Knockout       | Box Type                   | Recessed            |
| Number of Outlets                     | 0              | Depth Behind Device Plates | 2 in                |