




Wiremold
4000 Radiused Full Capacity Flat Elbow Fitting
Part No. G4011FO

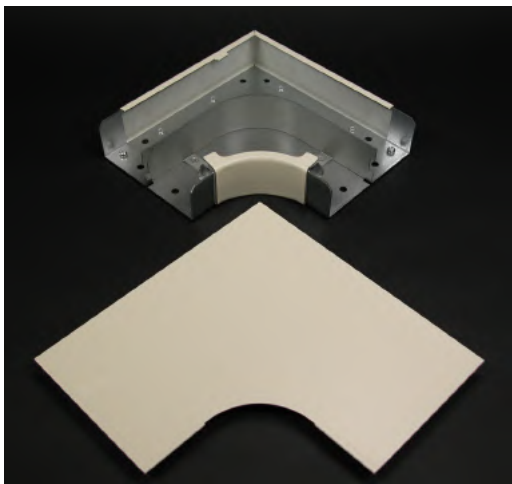

Full capacity 90 degree flat corner used in divided or undivided applications. Provides 2" (51mm) bend radius control for UTP, STP and fiber optic installations. Ideal for new installation when the cable is lay-in or pull-through.

Features & Benefits

Full capacity 90 degree flat corner used in divided or undivided applications. Provides 2" (51mm) bend radius control for UTP, STP and fiber optic installations. Ideal for new installation when the cable is lay-in or pull-through.

Specifications

General Info

Product Line	Wiremold	Color	Gray
UPC Number	786776536973	Country Of Origin	United States
Material	Steel	Product Series	4000 Series
Installation Location	On Wall	Application Sector	Commercial
Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Fitting		

Dimensions

Product Weight US	2.66 lb	Product Height US	1.75 in
Product Length US	8.75 in		

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E41751	cULus Listed	Yes
---------------------	--------	--------------	-----

Trade Programs

USMCA	Yes
-------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Is Pre-Wired	No	Indoor/Outdoor	Indoor
--------------	----	----------------	--------

Voltage	600.0 V
---------	---------