




Wiremold  
OFR Series Tee/Cross  
Part No. OFR15

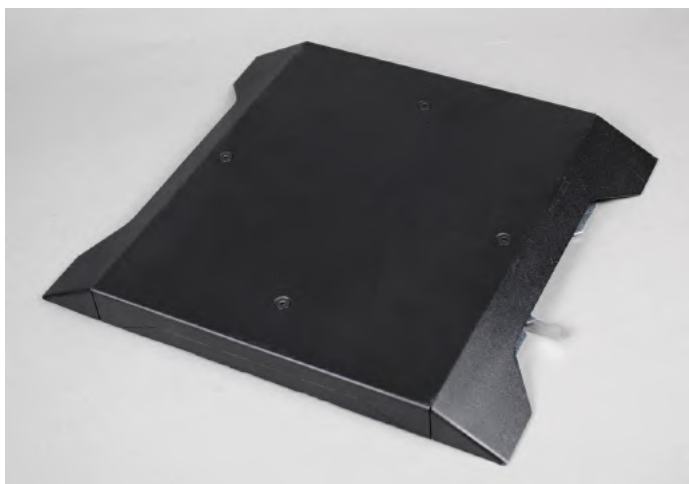

For branching OFR Series Raceway at right angles. Remove twistout on cover to make a cross.

## Features & Benefits

For branching OFR Series Raceway at right angles. Remove twistout on cover to make a cross.

## Specifications

### General Info

|                       |               |                    |                                                      |
|-----------------------|---------------|--------------------|------------------------------------------------------|
| Product Line          | Wiremold      | Color              | Black                                                |
| UPC Number            | 786776180152  | Country Of Origin  | United States                                        |
| Material              | Steel         | Product Series     | OFR Series                                           |
| Installation Location | On Floor      | Application Sector | Commercial                                           |
| Standard              | cETLus Listed | Warranty Type      | 1-Year from Installation or 2-Years from Day of Sale |
| Type                  | Fitting       |                    |                                                      |

### Dimensions

|                   |          |                   |           |
|-------------------|----------|-------------------|-----------|
| Product Width US  | 9.843 in | Product Weight US | 3.79 lb   |
| Product Height US | 1.0 in   | Product Length US | 11.375 in |

### Listing Agencies / 3rd Party Agencies

|            |     |
|------------|-----|
| ETL Listed | Yes |
|------------|-----|

---

Trade Programs

---

|       |     |
|-------|-----|
| USMCA | Yes |
|-------|-----|

---

Additional Information

---

|                |     |
|----------------|-----|
| RoHS Compliant | Yes |
|----------------|-----|

---

Technical Information

---

|              |    |                |        |
|--------------|----|----------------|--------|
| Is Pre-Wired | No | Indoor/Outdoor | Indoor |
|--------------|----|----------------|--------|

---

|         |         |
|---------|---------|
| Voltage | 300.0 V |
|---------|---------|

---