




Wiremold  
RC9A15TC Single-Service Poke-Thru Assembly, Black  
Part No. RC9A15TCBK

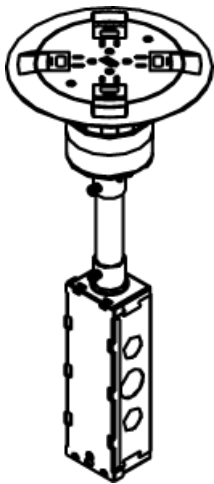

Prewired 15A quad receptacle can be wired as standard quad receptacle or isolated ground. Flange available painted in gray (GY), black (BK), ivory (VY), and brushed metal finishes in aluminum (AL) and brass (BS). Aluminum and brass flanges shipped with black cover. Brass flange also available with brass colored cover assembly (AB). Aluminum flange also available with aluminum colored cover assembly (AA). RC9 Series Poke-Thru Devices require a 3 1/16inch (78mm) diameter hole. Not designed to work with bare concrete or terrazzo. Floor covering thickness 1/8inch minimum.

## Features & Benefits

Prewired 15A quad receptacle can be wired as standard quad receptacle or isolated ground. Flange available painted in gray (GY), black (BK), ivory (VY), and brushed metal finishes in aluminum (AL) and brass (BS).

Aluminum and brass flanges shipped with black cover. Brass flange also available with brass colored cover assembly (AB). Aluminum flange also available with aluminum colored cover assembly (AA).

RC9 Series Poke-Thru Devices require a 3 1/16inch (78mm) diameter hole. Not designed to work with bare concrete or terrazzo. Floor covering thickness 1/8inch minimum.

## Specifications

### General Info

|                    |                                                      |                     |                                |
|--------------------|------------------------------------------------------|---------------------|--------------------------------|
| Product Line       | Wiremold                                             | Color               | Black                          |
| UPC Number         | 786564005582                                         | Country Of Origin   | Mexico                         |
| Material           | Steel                                                | Number of Knockouts | 2                              |
| Application Sector | Commercial, Education, Healthcare, Hospitality       | Standard            | UL Fire Classified, cULus, NEC |
| Warranty Type      | 1-Year from Installation or 2-Years from Day of Sale | Type                | Poke-Thru                      |

### Dimensions

|                   |             |                   |         |
|-------------------|-------------|-------------------|---------|
| Product Width US  | 7.0 in      | Product Weight US | 4.35 lb |
| Product Volume US | 808.5 cu in | Product Depth US  | 16.5 in |

|                                       |              |                               |          |
|---------------------------------------|--------------|-------------------------------|----------|
| Product Height US                     | 7.0 in       | Cubic Capacity                | 24.5 in³ |
| Core Hole Size                        | 3 in         |                               |          |
| Listing Agencies / 3rd Party Agencies |              |                               |          |
| cULus ListingNumber                   | E2961        | cULus Listed                  | Yes      |
| Additional Information                |              |                               |          |
| RoHS Compliant                        | Yes          | Product Environmental Profile | Yes      |
| Technical Information                 |              |                               |          |
| Floor Type                            | Carpet, Tile | Is Pre-Wired                  | Yes      |
| Service Capacity                      | Single       | Fire Rating                   | 2 hr     |
| Number of Outlets                     | 4            |                               |          |