




Wiremold
2400D RADIUS Divided Flat Elbow Fitting
Part No. V2411DFO

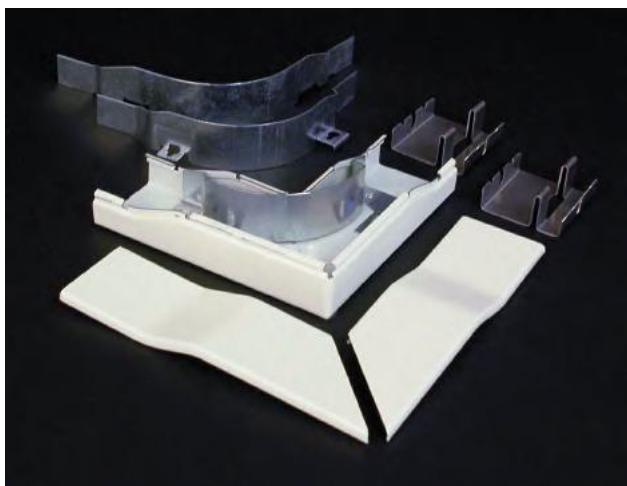

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

Features & Benefits

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

Specifications

General Info

Product Line	Wiremold	Color	Ivory
UPC Number	786776569582	Country Of Origin	United States
Material	Steel	Product Series	2400 Series
Installation Location	On Wall	Application Sector	Commercial
Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Fitting		

Dimensions

Product Width US	6.68 in	Product Weight US	1.27 lb
Product Height US	1.23 in	Product Length US	6.68 in

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E41751	cULus Listed	Yes
---------------------	--------	--------------	-----

Trade Programs

USMCA	Yes
-------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Is Pre-Wired	No	Indoor/Outdoor	Indoor
--------------	----	----------------	--------

Voltage	600.0 V
---------	---------