




Wiremold
4000 Radiused Full Capacity Internal Elbow Fitting
Part No. V4017FO

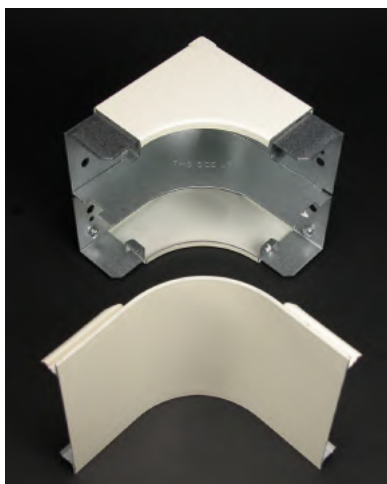

Full capacity, divided internal elbow. Provides 2" (51mm) cable bend radius control for UTP, STP and fiber optic installations. Ideal for new installations whether the cable is lay-in or pull-through.

Features & Benefits

Full capacity, divided internal elbow. Provides 2" (51mm) cable bend radius control for UTP, STP and fiber optic installations. Ideal for new installations whether the cable is lay-in or pull-through.

Specifications

General Info

Product Line	Wiremold	Color	Ivory
UPC Number	786776537055	Country Of Origin	United States
Material	Steel	Product Series	4000 Series
Installation Location	On Wall	Application Sector	Commercial
Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Fitting		

Dimensions

Product Width US	3.75 in	Product Weight US	2.0 lb
Product Depth US	1.75 in	Product Length US	3.75 in

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E41751	cULus Listed	Yes
---------------------	--------	--------------	-----

Trade Programs

USMCA	Yes
-------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Is Pre-Wired	No	Indoor/Outdoor	Indoor
--------------	----	----------------	--------

Voltage	600.0 V
---------	---------