




Wiremold
4047 Two-Gang Cover Rectangular Opening and Modular Furniture
Part No. V4047RF

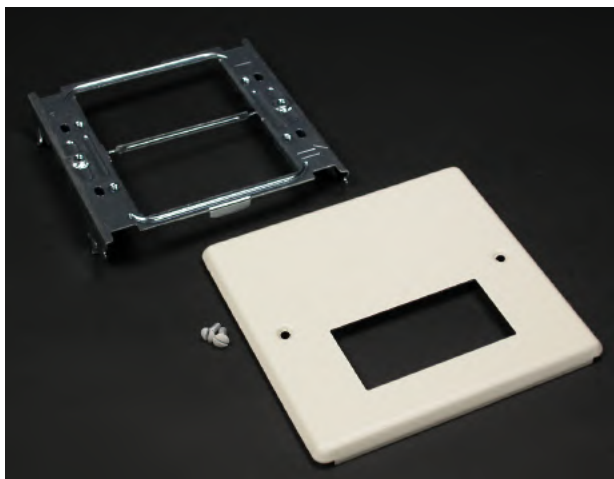

Accepts rectangular GFCI, Surge and Decorator style devices, modular furniture adapters and RJ45s. Does not accept 5507 Series Faceplates. NOTE: Certified to Canadian Safety Standards for sale in Canada. When ordering these products, change the "V" color prefix to "CV" or the "G" color prefix to "CG" to denote the Canadian versions.

Features & Benefits

Accepts rectangular GFCI, Surge and Decorator style devices, modular furniture adapters and RJ45s

Does not accept 5507 Series Faceplates

NOTE: Certified to Canadian Safety Standards for sale in Canada

When ordering these products, change the "V" color prefix to "CV" or the "G" color prefix to "CG" to denote the Canadian versions

Specifications

General Info

Product Line	Wiremold	Color	Ivory
UPC Number	786776041040	Country Of Origin	United States
Material	Steel	Product Series	4000 Series, 4047 Series, 6000 Series
Installation Location	On Wall	Application Sector	Commercial
Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.	Warranty Type	1-Year from Installation or 2-Years from Day of Sale
Type	Cover Plate		

Dimensions

Product Width US	4.75 in	Product Weight US	0.38 lb
Product Length US	5.125 in		
Trade Programs			
USMCA	Yes		
Additional Information			
RoHS Compliant	Yes	Product Environmental Profile	Yes
Technical Information			
Is Pre-Wired	No	Number of Gangs	2
Indoor/Outdoor	Indoor	Voltage	600.0 V